

# Xymphony 1U Rack Mount Keyboard Drawer with Integrated KVM Switch



## Benefits

- ▶ 1U keyboard drawer with integrated KVM switch
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front panel and two point lock

## Options

- MAC or SUN Micro keyboard options available



## Product Specifications

Console Port	
KB / MS	USB interface Drawer end : attached 6ft USB cable x 2 Server end : USB type A x 2

Physical		
Dimensions (W x D x H)	Product	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch
Weight	Net	10.9 kg / 24 lb


 

\* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Mounting Distance	
Single console drawer / Console w/ KVM drawer	560 ~ 790 mm 22 ~ 31.1 inch

Environment	
Operating temp.	-20 to 65°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	20~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration ( 11ms duration )
Vibration	10~300Hz 0.5G RMS random vibration

Compliance	
EMC	FCC & CE certified
Safety	CE / LVD certified
Environment	RoHS3 & REACH compliant

## Diagrams ( mm )

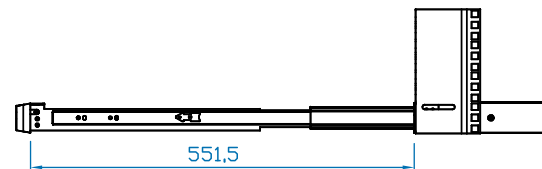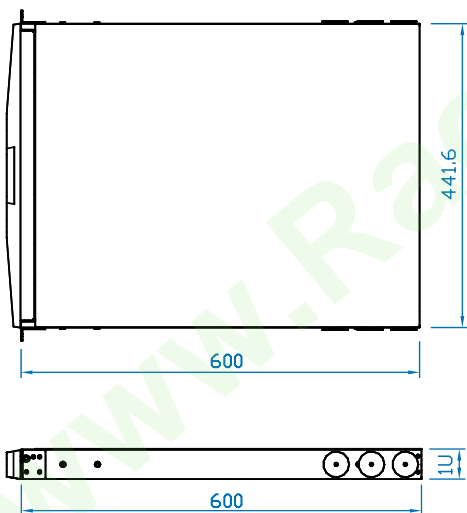

# Xymphony 1U Rack Mount Keyboard Drawer with Integrated KVM Switch

\*\* Resolution related to LCD specification

<b>2K KVM</b>	<b>IP</b>	Remote	8-port
	0	0	LCDK1032

**2K KVM Cable**




Resolution 16:9 - max. 2560 x 1440  
Support \*\*: 16:10 - max. 1920 x 1200  
4:3 - max. 1600 x 1200

LCD-A3011 (6 ft) DVI-D KVM cable  
LCD-A3012 (6 ft) HDMI KVM cable

<b>DVI-D KVM</b>	<b>IP</b>	Remote	12-port
	0	0	LCDK1018

**DVI-D USB KVM Cable**




Resolution 16:10 - max. 1920 x 1200  
Support \*\*: 16:9 - max. 1920 x 1080  
4:3 - max. 1600 x 1200

LCD-A3005 (6 ft)  
LCD-A3006 (15 ft)

<b>Cat6 Matrix KVM</b>	<b>IP</b>	Remote	8-port	16-port	32-port
	1	1	-	LCDK1068-31	LCDK1069-31
	2	1	-	LCDK1068-42	LCDK1069-42
	0	1	-	LCDK1065-2	LCDK1067-2
	0	2	-	LCDK1065-3	LCDK1067-3
	0	3	-	LCDK1065-4	LCDK1067-4

**Cat6 KVM Dongle**



Resolution 16:10 - max. 1920 x 1200  
Support \*\*: 16:9 - max. 1920 x 1080  
4:3 - max. 1600 x 1200


LCD-A2005 DP - USB dongle  
LCD-A2004 HDMI - USB dongle  
LCD-A2003 DVI - USB dongle  
LCD-A2001 VGA - USB dongle  
LCD-A2002 VGA - PS/2 dongle

\*\* Resolution related to LCD specification

<b>Cat6 Combo KVM</b>	<b>IP</b>	Remote	8-port	16-port	32-port
	1	0	LCDK1058	LCDK1059	LCDK1060
	0	1	LCDK1055	LCDK1056	LCDK1057
	0	0	LCDK1050	LCDK1051	LCDK1052

<b>DB-15 Matrix KVM</b>	<b>IP</b>	Remote	8-port	16-port
	1	1	LCDK1063-31	LCDK1064-31
	2	1	LCDK1063-42	LCDK1064-42
	0	1	LCDK1061-2	LCDK1062-2
	0	2	LCDK1061-3	LCDK1062-3
	0	3	LCDK1061-4	LCDK1062-4

**DB-15 VGA USB KVM Cable**



Resolution 16:10 - max. 1920 x 1200  
Support : 16:9 - max. 1920 x 1080  
4:3 - max. 1600 x 1200

 

LCD-A1014 (6 ft) LCD-A1015 (10 ft) LCD-A1016 (15 ft)

\*\* Resolution related to LCD specification


<b>DB-15 Combo KVM</b>	<b>IP</b>	Remote	8-port	16-port
	1	0	LCDK1053	LCDK1054
	0	1	LCDK1029	LCDK1030
	0	0	LCDK1027	LCDK1028

## Standard Keyboard

**N** keyboard integrated with touchpad

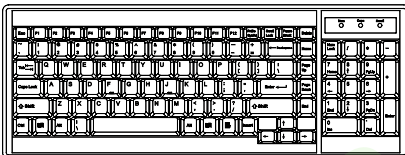

**B** keyboard integrated with trackball

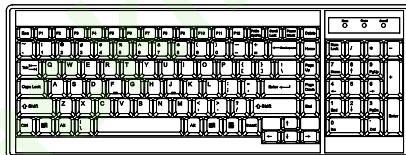

## Supporting layouts

**America** United States

**EMEA** United Kingdom Germany France Spain Italy

**Asia** Japan Korea

## Keyboard Options

\* US layout only

**Mn** Mac keyboard with touchpad



**Sn** SUN keyboard with touchpad

**Mb** Mac keyboard with trackball

**Sb** SUN keyboard with trackball

