



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)


## Metered Rack PDU

**Outlets.** The Rack PDU has sixteen (16) NEMA 5-15 outlets.

**Display interface.** A digital display shows the aggregate current used by the Rack PDU.

**Power cord.** The 10-foot (3.05-meter) power cord terminates with a NEMA 5-15 connector.

**AD-016-515-15A-515**

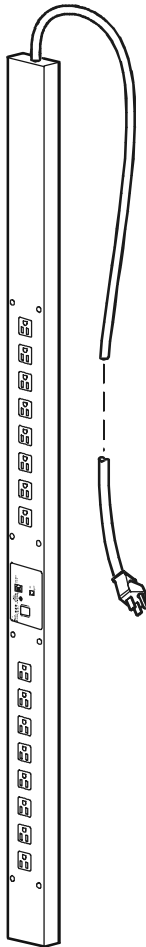

# Specifications

---

## Electrical

---

Input connector	NEMA 5-15 plug
Output connectors	(16) NEMA 5-15 outlets
Nominal input voltage	100 – 120 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	47– 63 Hz

---

## Physical

---

Dimensions (H × W × D)	49.00 × 2.20 × 1.75 in (126.46 × 5.59 × 4.45 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)

---

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5 – 95% RH Non-condensing
Storage	5 – 95% RH Non-condensing

---

## Compliance

---

EMC verification	VCCI, FCC Part 15 Class A ICES-003
Safety verification	UL/cUL 60950 Listed METI-DENAN

---