



Synergy Global Technology Inc

www.RackmountMart.com


Metered Rack PDU

Outlets. The Rack PDU has twenty-four (24) NEMA 5-20R outlets.

Digital display. A digital display shows the aggregate current used by the Rack PDU.

Power cord. The 9.84 feet (3-meter) power cord terminates with a NEMA L5-20P connector.

AD-024-520-20A-L520

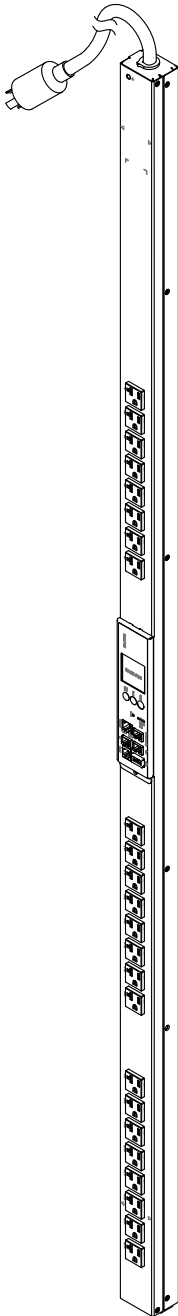

Specifications

Electrical

Input connector	NEMA L5-20P plug
Output connectors	(24) NEMA 5-20R outlets
Nominal input voltage	100VAC , 120VAC
Input frequency	50/60 Hz

Physical

Dimensions (H × W × D)	70.50 x 2.18 x 1.72in (179.10 x 5.50 x 4.40 cm)
Shipping dimensions (H × W × D)	78.98 x 6.48 x 4.26 in (200.60 x 16.40 x 10.8 cm)
Weight	12.3 lb (5.59 kg)

Environmental

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature 11/2008	
Operating	23 to 113° F (-5 to 45° C)
Storage	-13 to 149° F (-25 to 65° C)
Humidity	
Operating	5 – 95% RH non-condensing
Storage	5 – 95% RH non-condensing

Compliance

EMC verification	FCC Part 15 Class A ICES-003
Safety verification	UL 60950-1 UL Listed

Sustainable Offer Status

RoHS	Compliant
REACH	REACH:Contains No SVHCs



Synergy Global Technology Inc

www.RackmountMart.com