



Synergy Global Technology Inc

www.RackmountMart.com


Metered Rack PDU

Outlets. The Rack PDU has twenty-four (24) NEMA 5-20 outlets.

Digital display. The interface uses a digital display that shows aggregate current being used by the Rack PDU.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA L5-30 connector.

AD-024-520-30A-L530

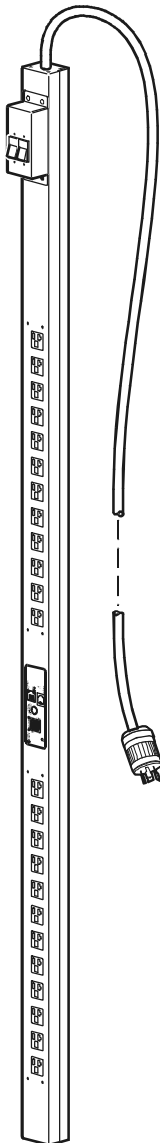

Specifications

Electrical

Input connector	NEMA L5-30 plug
Output connectors	(24) NEMA 5-20 outlets
Nominal input voltage	120 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	50/60 Hz

Physical

Dimensions (H × W × D)	63.75 x 2.19 x 1.73 in (161.92 x 5.56 x 4.39 cm)
Shipping dimensions (H × W × D)	84.00 x 6.00 x 5.00 in (213.36 x 15.24 x 12.7 cm)
Weight	12.50 lb (5.67 kg)

Environmental

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 115° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5 – 95% RH Non-condensing
Storage	5 – 95% RH Non-condensing

Compliance

EMC verification	FCC Class A ICES-003 Class A
Safety verification	UL, cUL 60950



Synergy Global Technology Inc

www.RackmountMart.com