


Metered Rack PDU

Outlets. The PDU has sixteen (16) NEMA 5-20 outlets.

Digital display. A digital display shows aggregate current being used per bank by the PDU.

Power cord. The 12-ft (3.65-m) power cord terminates with a NEMA L5-30P connector.

AD-216-520-30A-L530

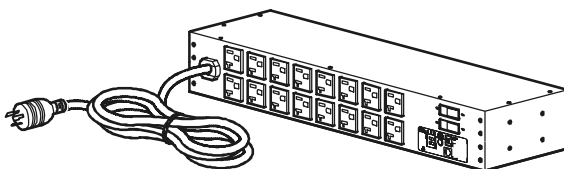

Specifications

Electrical

Input connector	NEMA L5-30P
Cord length	12 ft (3.65 m)
Nominal input voltage	120 V
Input frequency	50–60 Hz
Acceptable input voltage	±10% of nominal voltage
Maximum input current total (bank)	24 A
Nominal output voltage	120 V
Maximum output current (outlet)	16 A
Maximum output current (bank)	20 A
Output connectors	(16) NEMA 5-20
Overload protection	(2) 20-A single-pole circuit breakers

Physical

Dimensions (H × W × D)	3.48 × 17.47 × 4.41 in (8.83 × 44.37 × 11.20 cm)
Shipping dimensions (H × W × D)	5.50 × 20.00 × 14.50 in (13.97 × 50.80 × 36.83 cm)
Weight	7.40 lb (2.76 kg)

Environmental

Elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113°F (–5 to 45°C)
Storage	–13 to 149°F (–25 to 65°C)
Humidity	
Operating	5–95%, non-condensing
Storage	5–95%, non-condensing

Approvals

Safety Certification	UL/C-UL listed to UL/CSA 60950
Emissions	FCC Class A, ICES-003
