



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)


## Metered Rack PDU

**Outlets.** The Rack PDU has twenty-one (21) NEMA 5-20 outlets and six (6) NEMA L6-20 outlets.

**Display interface.** A digital display shows the aggregate current used by the Rack PDU.

**Power cord.** The 10-foot (3.05-meter) power cord terminates with a L21-20 connector.

**ADH-027-N-20A-L212-A**

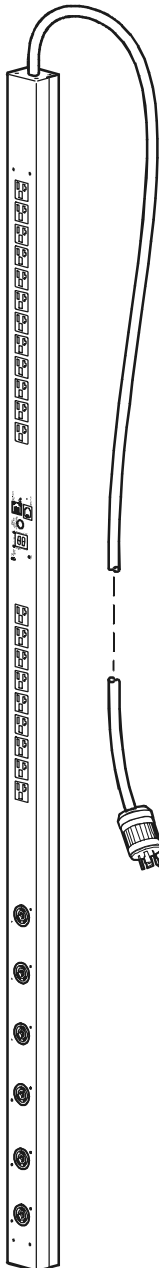

# Specifications

---

## Electrical

---

Input connector	NEMA L21-20 plug
Output connectors	(21) NEMA 5-20 outlets (6) NEMA L6-20 outlets
Nominal input voltage	120/208 VAC, 3-phase
Acceptable input voltage	± 10% of nominal voltage
Input frequency	47–63 Hz

---

## Physical

---

Dimensions (H × W × D)	70.00 × 2.20 × 1.75 in (177.80 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	12 lb (5.4 kg)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 113° F (–5 to 45° C)
Storage	–13 to 149° F (–25 to 65° C)
Humidity	
Operating	5–95% RH Non-condensing
Storage	5–95% RH Non-condensing

---

## Compliance

---

EMC	FCC Part 15 Class A ICES-003 Class A
Safety verification	UL/cUL 60950 Listed

---