



Synergy Global Technology Inc

www.RackmountMart.com


Metered Rack PDU

Outlets. The Rack PDU has twenty-one (21) NEMA 5-20 outlets and six (6) NEMA L6-20 outlets.

Display interface. A digital display shows aggregate current being used by the Rack PDU.

Power cord. The 3-foot (0.91-meter) power cord terminates with a NEMA L21-20 connector.

ADH-027-N-20A-L212

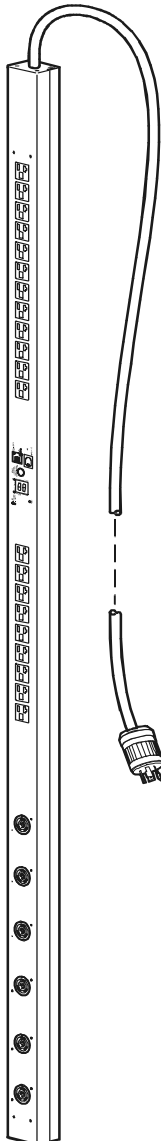

Specifications

Electrical

Input connector	NEMA L21-20 plug
Output connectors	(21) NEMA 5-20 outlets, (6) NEMA L6-20 outlets
Nominal input voltage	120/208 VAC 3-phase
Acceptable input voltage	± 10% of normal voltage
Input frequency	47–63 Hz

Physical

(H × W × D)	70.00 × 2.19 × 1.73 in (177.80 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	12 lb (5.4 kg)

Environmental

Maximum elevation (above MSL)	
Operating	15 000 ft (4500 m)
Storage	50 000 ft (15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH Non-condensing
Storage	5–95% RH Non-condensing

Compliance

EMC verification	FCC Part 15 Class A ICES-003 Class A
Safety verification	UL, cUL 60950



Synergy Global Technology Inc

www.RackmountMart.com