



**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)


## Switched Rack PDU

**Outlets.** The Rack PDU has sixteen (16) IEC-320-C13 outlets.

**Power cord.** The 12-foot (3.65-meter) power cord terminates with a NEMA L6-30 connector.

**Digital display.** The digital display allows you to monitor the aggregate current of the Switched Rack PDU and to establish a network connection using the network port.

**AS-216-C13-30A-L630**

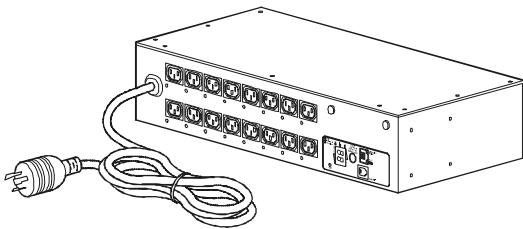

# Specifications

---

## Electrical

---

Input connector	NEMA L6-30 connector
Output connectors	16 IEC-320-C13 outlets
Nominal input voltage	200–240 VAC
Acceptable input voltage	± 10% of normal voltage
Maximum input current	30 A (24 A UL (C-UL) derated)
Input frequency	50/60 Hz
Overcurrent protection (internal)	(2) 20 A, 2-pole circuit breakers

---

## Physical

---

Size (H × W × D)	3.5 × 17.5 × 10.0 in (8.89 × 44.45 × 25.4 cm)
Shipping Dimensions (H × W × D)	5.75 × 20.25 × 20.25 in (14.60 × 51.43 × 51.43 cm)
Weight	13.9 lb ( 6.30 kg)

---

## Environmental

---

Elevation (above MSL)	
Operating	0–10,000 ft (0–3000 m)
Storage	0–50,000 ft (0–15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

---

## Compliance

---

Safety verification	UL (C-UL) listed, PSE
EMC verification	FCC Part 15 Class A, ICES-003 Class A, VCCI-A

---