



Open Wall Mount Frame Assembly Instructions

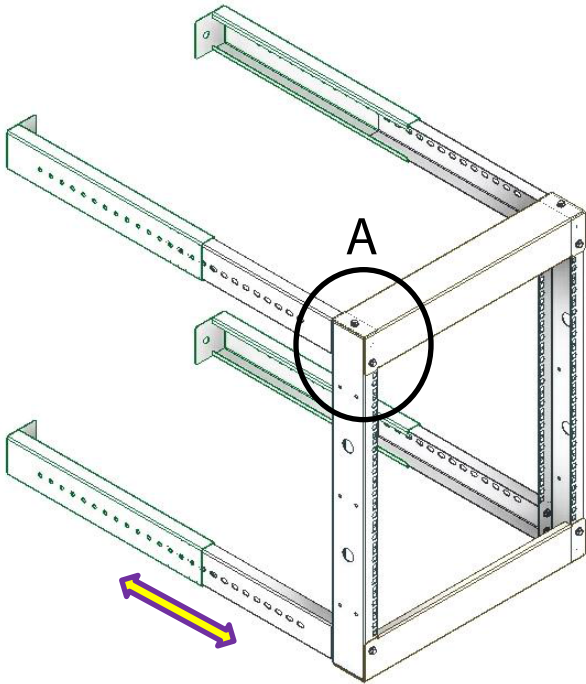


Assembly view

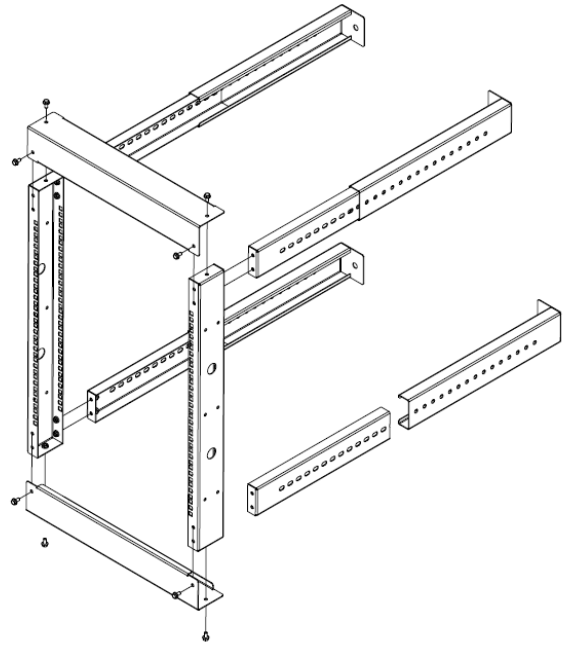

Exploded view

Model	U/RMS	Height	External Width	Adjustable Depth
WR1007-F	6U	17"	20.25"	18"-30"
WR1005-F	8U	20.5"	20.25"	18"-30"
WR1008-F	9U	22.25"	20.25"	18"-30"
WR1003-F	12U	27.5"	20.25"	18"-30"
WR1006-F	16U	34.5"	20.25"	18"-30"
WR1004-F	20U	41.5"	20.25"	18"-30"

Open Wall Mount Frame Assembly Instructions

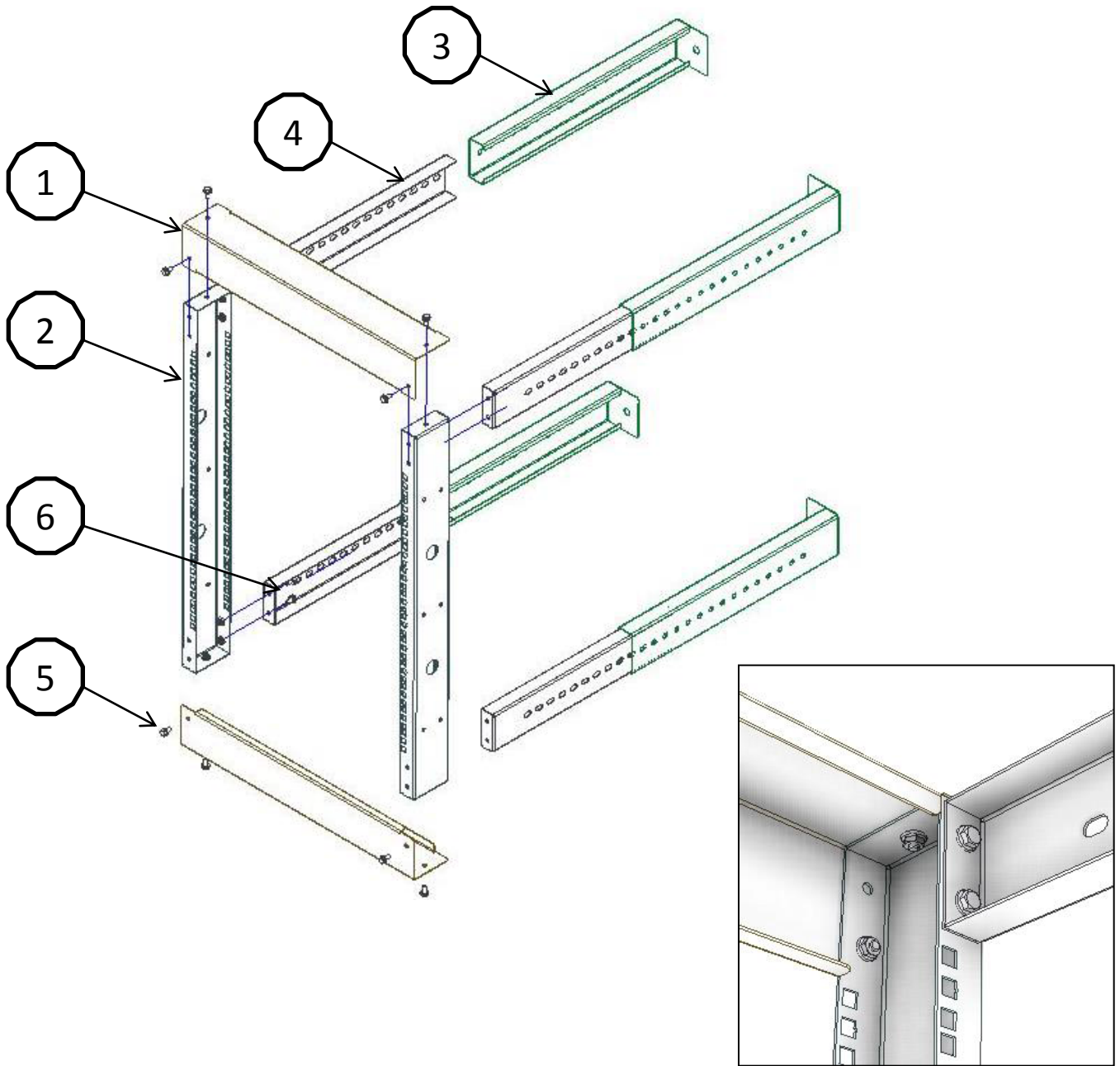

Detail-A

- | | |
|-----------------------------------|---------------------------------|
| 1) Rack Frame Member Top & Bottom | 5) Hex Flange Bolt, M6 X 12 L |
| 2) Vertical Member | 6) Hex Flange Nut ,M6 |
| 3) Depth Member A | 7) Hardware Kit (separate pack) |
| 4) Depth Member B | |