


ID-H19P-LED 19" High Brightness LCD with LED-backlit Display

Universal open frame mounting

 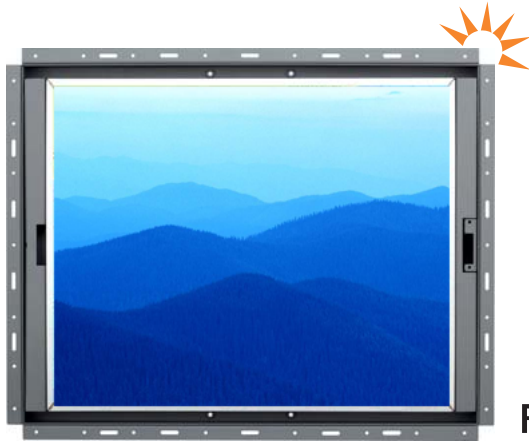


Display Benefits

- ▶ 19" LCD with high brightness 1000 cd/m²
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact

Options

- HDMI, DVI-D, S-Video + BNC & Audio
- 3G / HD / SD-SDI Broadcast-grade input
- **MCS** Multi-display control solution
- H19" Touchscreen : Capacitive, Resistive
- MIL-type or lockable connector
- 48V or 24VDC power
- TV - PAL or NTSC
- Auto / switch dimming



Standard I/O : VGA only

Options I/O : BNC + S-Video, Audio, TV, USB for touchscreen
HDMI or DVI-D (either one)

Specifications

• LCD Panel

Size (diagonal) : 19" TFT
 Max resolution : 1280 x 1024
 Brightness (cd/m²) : 1000
 Backlight : LED
 Colors : 16.7 M
 Contrast ratio (typ) : 1000 : 1
 Viewing angle (H/V) : 160° x 160°
 Active area (mm) : 376 x 301
 MTBF (hrs) : 50,000
 Signal input : VGA

• Weight

Net : 6 kgs (13.2 lbs)

• Mounting :

Universal mount / VESA mount

• Environmental

Operating : 0 to 50°C Degree
 Storage : -5 to 60°C Degree
 Relative humidity : 5~90%, non-condensing
 Shock : 10G acceleration (11 ms duration)
 Vibration : 5~500Hz 1G RMS random vibration

• Casing Color :

Dark grey (RAL 7037)

• Regulatory :

FCC, CE

• Power

Input : Auto-sensing 100 to 240VAC, 50 / 60Hz
 Consumption : Max. 84 Watt, Standby 5 Watt

• Dimensions

Product : 474 x 58 x 381 mm / 18.6 x 2.3 x 15 inch

Diagrams (mm)

Front View

Side View

Rear View

