




Benefits

- ▶ 1U 17" 4K LCD console drawer
- ▶ Dual slide - LCD and keyboard slide independently
- ▶ 3840 x 2160 native resolution / 16.7M colors (8-bit)
- ▶ 1920 x 1080 & 1920 x 1200 resolution support
- ▶ Display port 1.2 video input / USB KB/MS
- ▶ Built-in dual stereo speakers
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front handle and two point lock

Options

- HDMI 2.0 video input
- 3G / HD / SD-SDI Broadcast-grade input
- DC power : 12V / 24V / 48V / 110V / 125V
- MAC or SUN Micro keyboard options available

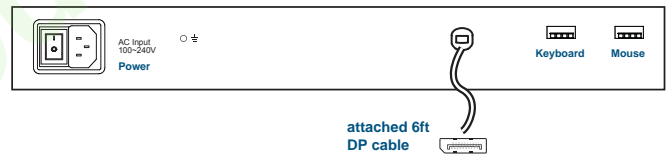

Product Specifications

Console Port	
Video input attached 6ft DP cable	Display port 1.2
KB / MS bundled 6ft USB cable x 2	USB type A

Video Option		
Digital	HDMI	HDMI 2.0 / HDCP 2.2

LCD Panel	
Panel size (diagonal)	17.3"
Native resolution	3840 x 2160
Brightness (cd/m²)	400
Contrast ratio (typ.)	1000 : 1
Colors	16.7 M, 8-bit
Viewing angle (L/R/U/D)	89/89/89/89
Response time (ms)	16
Dot pitch (mm)	0.0995
Display area (mm)	382.12H x 214.94V
Surface treatment	Anti-glare
Surface hardness	3H
Backlight type	LED
MTBF (hrs)	20,000

Audio Option		
Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 29W / Max. 38W
	Power saving mode	Max. 9W / Max. 18W
	Power button off	Max. 2W / Nil

Physical		
Product (W x D x H)	Single console	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch
	Console w/ KVM	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch
Net weight	Single console	12 kg / 26.4 lb
	Console w/ KVM	13 kg / 28.6 lb


* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	20~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Mounting Distance	
Single console drawer / Console w/ KVM drawer	660 ~ 870 mm 26 ~ 34.3 inch

Compliance	
EMC	FCC & CE certified
Safety	CE / LVD certified
Environment	RoHS2 & REACH compliant

4K 60Hz KVM	IP	Remote	8-port
	0	0	LCD1U17-42-8HD

 

**** Resolution related to LCD specification**

4K KVM Cable


LCD-A3009 (6 ft)
DP KVM cable

LCD-A3008 (6 ft)
HDMI KVM cable

Resolution 16:9 - max. 3840 x 2160
Support **: 16:10 - max. 1920 x 1200
 4:3 - max. 1600 x 1200

Standard Keyboard

N G keyboard integrated with touchpad

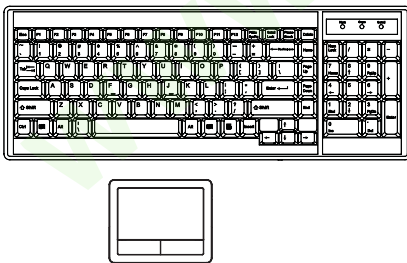

Supporting layouts

<p>America</p> <p>United States</p>											
<p>EMEA</p>	<table border="0" style="width: 100%;"> <tr> <td style="text-align: center;"> United Kingdom </td> <td style="text-align: center;"> Germany </td> <td style="text-align: center;"> France </td> <td style="text-align: center;"> Spain </td> <td style="text-align: center;"> Norway </td> </tr> <tr> <td style="text-align: center;"> Italy </td> <td style="text-align: center;"> Russia </td> <td style="text-align: center;"> Switzerland </td> <td style="text-align: center;"> Netherlands </td> <td style="text-align: center;"> Portugal </td> </tr> </table>	 United Kingdom	 Germany	 France	 Spain	 Norway	 Italy	 Russia	 Switzerland	 Netherlands	 Portugal
 United Kingdom	 Germany	 France	 Spain	 Norway							
 Italy	 Russia	 Switzerland	 Netherlands	 Portugal							
<p>Asia</p>	<table border="0" style="width: 100%;"> <tr> <td style="text-align: center;"> China </td> <td style="text-align: center;"> Japan </td> <td style="text-align: center;"> Korea </td> <td style="text-align: center;"> Arabia </td> <td style="text-align: center;"> Turkey </td> </tr> </table>	 China	 Japan	 Korea	 Arabia	 Turkey					
 China	 Japan	 Korea	 Arabia	 Turkey							

Keyboard Options

* US layout only

Mn Mac keyboard with touchpad



Sn S keyboard with touchpad

