




**Benefits**

- ▶ 2U 17" 4K LCD console drawer
- ▶ Dual slide - LCD and keyboard slide independently
- ▶ 3840 x 2160 native resolution / 16.7M colors ( 8-bit )
- ▶ 1920 x 1080 & 1920 x 1200 resolution support
- ▶ Display port 1.2 video input / USB KB/MS
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Built-in dual stereo speakers
- ▶ Short depth design of 480mm
- ▶ One Man installation design
- ▶ Enhanced aesthetics with molded front handle and two point lock

**Options**

- HDMI 2.0 video input
- 3G / HD / SD-SDI Broadcast-grade input
- DC power : 12V / 24V / 48V / 110V / 125V
- MAC or SUN Micro keyboard options available
- Touchscreen : Projected Capacitive 10-pt / Resistive 1-pt

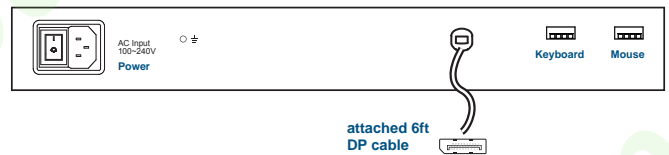

**Product Specifications**

Console Port	
Video input attached 6ft DP cable	Display port 1.2
KB / MS bundled 6ft cable : USB x 2	USB type A

LCD Panel	
Panel size ( diagonal )	17.3"
Native resolution	3840 x 2160
Brightness ( cd/m <sup>2</sup> )	300
Contrast ratio ( typ )	1000 : 1
Colors	16.7 M, 8-bit
Viewing angle ( L/R/U/D )	89/89/89/89
Response time ( ms )	16
Dot pitch ( mm )	0.0995
Display area ( mm )	382.12H x 214.94V
Surface treatment	Anti-glare
Surface hardness	3H
Backlight type	LED
MTBF ( hrs )	20,000

Video Option		
Digital	HDMI	HDMI 2.0 / HDCP 2.2

Audio Option		
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 29W / Max. 38W
	Power saving mode	Max. 9W / Max. 18W
	Power button off	Max. 2W / Nil

Physical		
Product ( W x D x H )	Single console	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch
	Console w/ KVM	442 x 480 x 88 mm 17.4 x 18.9 x 3.5 inch
Net weight	Single console	20.4 kg / 44.9 lb
	Console w/ KVM	21.1 kg / 46.4 lb

 
\* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	20~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration ( 11ms duration )
Vibration	10~300Hz 0.5G RMS random vibration

Mounting Distance	
Single console drawer / Console w/ KVM drawer	490 ~ 700 mm 19.3 ~ 27.6 inch

Compliance	
EMC	FCC & CE certified
Safety	CE / LVD certified
Environment	RoHS2 & REACH compliant

4K 60Hz KVM	IP	Remote	8-port
	0	0	LCD2U17-07-8HD



**\*\* Resolution related to LCD specification**

**4K KVM Cable**

LCD-A3009 (6 ft)  
DP KVM cable



LCD-A3008 (6 ft)  
HDMI KVM cable

Resolution 16:9 - max. 3840 x 2160  
Support \*\*: 16:10 - max. 1920 x 1200  
                  4:3 - max. 1600 x 1200

**Standard Keyboard**

**N** keyboard integrated with touchpad

**B** keyboard integrated with trackball

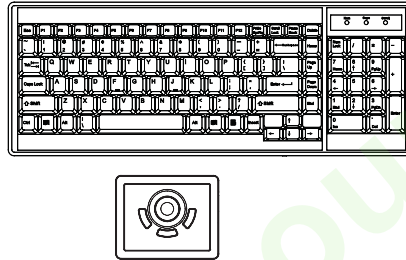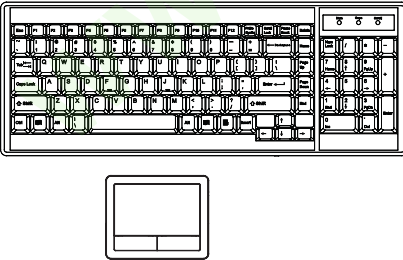

**Supporting layouts**

America United States				
United Kingdom	Germany	France	Spain	Norway
EMEA				
Italy	Russia	Switzerland	Netherlands	Portugal
Asia				
China	Japan	Korea	Arabia	Turkey

**Keyboard Options**

\* US layout only

**Mn** Mac keyboard with touchpad



**Sn** SUN keyboard with touchpad

**Mb** Mac keyboard with trackball

**Sb** SUN keyboard with trackball

