


LCDR8U19-09 19" widescreen Rackmount Quad LCD Display

Display Features & Benefits

- ▶ 8U 19" widescreen rackmount LCD
- ▶ Built-in Quad Display
- ▶ Ideal for CCTV security & industrial control


Option ● DC power : 12V / 24V / 48V / 110 ~ 125V

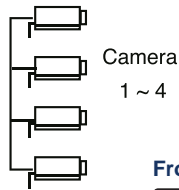

Front QD membrane button



I / O window

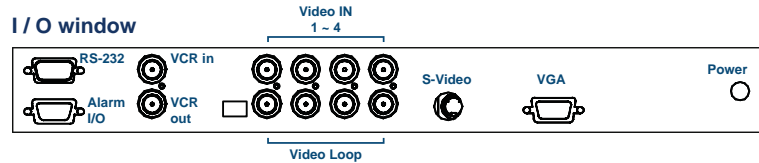

Specifications

• LCD Panel

| | |
|------------------------|--------------------|
| Manufacturer : | |
| Size (diagonal) : | 19" widescreen TFT |
| Max resolution : | 1440 x 900 |
| Brightness (cd/m2) : | 250 |
| Backlight : | LED |
| Colors : | 16.7M |
| Contrast ratio (typ) : | 1000 : 1 |
| Viewing angle (H/V) : | 160° x 160° |
| Active area (mm) : | 408 x 255 |
| MTBF (hrs) : | 30,000 |
| Signal input : | VGA |

• **Power Input :** Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption

| | |
|---------------------|----------|
| Screen on : | Max. 25W |
| Power saving mode : | Max. 4W |
| Power button on : | Max. 1W |

• Environmental

| | |
|--------------------------|------------------------------------|
| Operating temperature : | 0 to 55°C degree |
| Storage temperature : | -20 to 60°C degree |
| Operating humidity : | 20~90%, non-condensing |
| Storage humidity : | 5 ~90%, non-condensing |
| Operating altitude : | 16,000 ft |
| Non-operating altitude : | 40,000 ft |
| Shock : | 10G acceleration (11ms duration) |
| Vibration : | 5~500Hz 1G RMS random vibration |

• **Casing Color :** Black (RAL 9005)

• Regulatory

| | |
|-----------------|-------------------------|
| Safety : | FCC & CE certified |
| Environmental : | RoHS2 & REACH compliant |

• Weight

Net : 9.5 kgs / 20.9 lbs

• Dimensions

Product : 480 x 72.5 x 354.8 mm / 18.9 x 2.9 x 14 inch

Diagrams (mm)

