



**Display Benefits**

- ▶ 6.5" LCD with resolution 640 x 480
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact
- ▶ Protective 3mm glass

**Options**

 
- S-Video + BNC & Audio
- 48V, 24V or 12VDC power
- 6.5" Touchscreen : Capacitive, Resistive
- TV - Analog

6mm aluminum front bezel with optional


NEMA 4 / IP65 front protection



**Standard I/O**



**BNC-SPK upgrade I/O**

 

**Specifications**

• **LCD Panel**

Manufacturer :	<b>AUO</b>
Size (diagonal) :	6.5" TFT
Max resolution :	640 x 480
Brightness (cd/m2) :	800
Backlight :	LED
Colors :	262 K
Contrast ratio (typ) :	600 : 1
Viewing angle (H/V) :	160° x 140°
Active area (mm) :	132 x 99
MTBF (hrs) :	50,000
Signal input :	VGA

• **Weight**

Net / Gross : 1.5 kgs ( 3.3 lbs )

• **Mounting :**

Panel mount / VESA mount

• **Environmental**

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration ( 11 ms duration )
Vibration :	5~500Hz 1G RMS random vibration

• **Casing Color :**

Black front panel ( RAL 9005 )  
Dark grey rear case ( RAL 7037 )

• **Regulatory :**

FCC, CE

• **Power**


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 40 Watt, Standby 5 Watt

• **Dimensions**


Product : 255 x 68 x 182 mm / 10 x 2.7 x 7.2 inch

**Diagrams ( mm )**

**Front View**

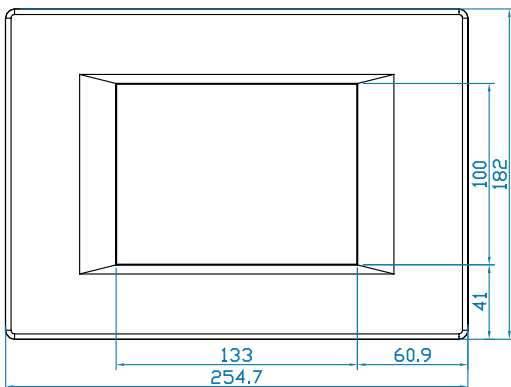

**Side View**

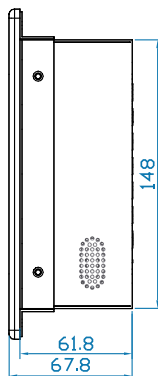

**Rear View**

