



Display Benefits

- ▶ 10.4" LCD with resolution 800 x 600
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact
- ▶ Protective 3mm glass

Options

 
- S-Video + BNC & Audio
- 48V, 24V or 12VDC power
- 10.4" Touchscreen : Capacitive, Resistive
- TV - Analog

6mm aluminum front bezel with optional


NEMA 4 / IP65 front protection



Standard I/O



BNC-SPK upgrade I/O

 

Specifications

• **LCD Panel**

Manufacturer :	AUO
Size (diagonal) :	10.4" TFT
Max resolution :	800 x 600
Brightness (cd/m2) :	230
Backlight :	LED
Colors :	262 K
Contrast ratio (typ) :	500 : 1
Viewing angle (H/V) :	160° x 130°
Active area (mm) :	211 x 158
MTBF (hrs) :	30,000
Signal input :	VGA

• **Weight**

Net / Gross : 2.5 kgs (5.5 lbs)

• **Mounting :**

Panel mount / VESA mount

• **Environmental**

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• **Casing Color :**

Black front panel (RAL 9005)
Dark grey rear case (RAL 7037)

• **Regulatory :**

FCC, CE

• **Power**


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 40 Watt, Standby 5 Watt

• **Dimensions**


Product : 285 x 63 x 222 mm / 11.2 x 2.5 x 8.7 inch

Diagrams (mm)

Front View

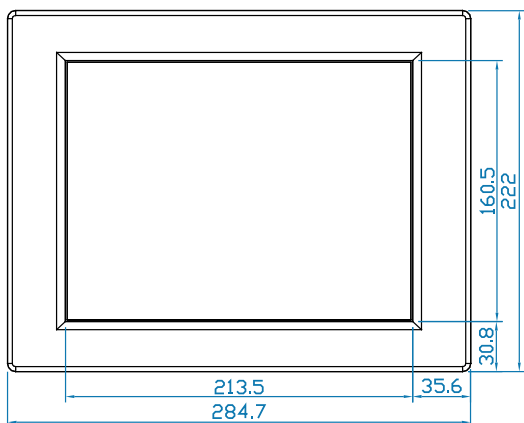

Side View

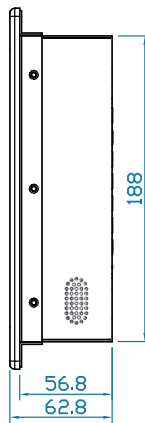

Rear View

