

ID-H42Aw-LED 42" Widescreen Full HD High Brightness LCD w/ LED-backlit Display

NEMA 4 / IP65 front protection



Display Benefits

- ▶ 42" widescreen LCD with high brightness 1500 cd/m2
- ▶ **Full HD** LCD display with 1080p resolution
- ▶ PIP & Picture by Picture viewing efficiency
- ▶ 8mm aluminum front bezel with protective glass & water proof sealed gasket
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact
- ▶ Standard with HDMI, DVI-D, VGA, S-Video, RCA, Audio & remote controller

Options

- 3G / HD / SD-SDI Broadcast-grade input
- **MC** Multi-display control solution
- 48V or 24VDC power
- MIL-type or lockable connector
- TV - Analog
- Auto / switch dimming

Basic I/O



Specifications

• LCD Panel

Size (diagonal) :	42" Widescreen TFT
Max resolution :	1920 x 1080
Brightness (cd/m2) :	1500
Backlight :	LED
Colors :	16.7 M
Contrast ratio (typ) :	3000 : 1
Viewing angle (H/V) :	178° x 178°
Active area (mm) :	930 x 523
MTBF (hrs) :	50,000
Signal input :	HDMI / DVI-D / VGA / S-Video / RCA

• Weight

Net : 35.7 kgs (78.5 lbs)

• Mounting :

Wall-mount / VESA mount

• Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• Casing Color :

Black (RAL 9005)

• Regulatory :

FCC, CE, RoHS

• Power


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 200 Watt, Standby 20 Watt

• Dimensions


Product : 1051 x 105.8 x 644 mm / 41.4 x 4.2 x 25.4 inch

Diagrams (mm)

Front View

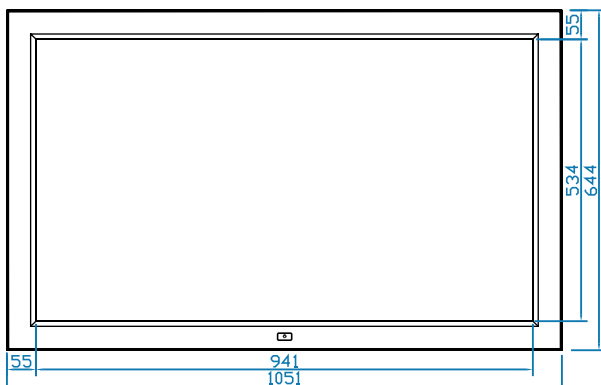

Side View

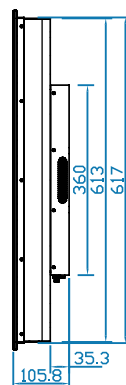

Rear View

