

www.RackmountMart.com



Drawer Features & Display Benefits

- ▶ 1U 17" widescreen LCD console drawer with VGA and DVI-D
- ▶ Direct Support SUN Micro native 1152 x 900 and Full HD 1080p resolution
- ▶ 104-key keyboard with SUN hot-key and either touchpad or trackball
- ▶ New enhanced aesthetics with molded front handle
- ▶ Short depth design of 480mm (18.9") only
- ▶ Front USB port for device access (USB Hub KVM only)
- ▶ 2 post rack mounting available

Options

- DC power : 12V / 24V / 48V / 110 ~ 125V

Specifications

• LCD Panel

- Size (diagonal) : 17.3" widescreen TFT
- Max resolution : 1920 x 1080
- Brightness (cd/m2) : 400
- Backlight : LED
- Colors : 16.7 M, 8-bit
- Contrast ratio (typ) : 600 : 1
- Viewing angle (H/V) : 160° x 140°
- Active area (mm) : 382 x 215
- MTBF (hrs) : 50,000
- Signal input : VGA or DVI-D

- Speaker :** Built-in Dual Stereo Speakers (option) 2W x 2

- Casing Color :** Black (RAL 9005)

- Power Input :** Auto-sensing 100 to 240VAC, 50 / 60Hz

• Power Consumption (single console)

- Screen on : Max. 25W
- Power saving mode : Max. 4W
- Power button on : Max. 1W

• Environmental

- Operating temperature : 0 to 55°C degree
- Storage temperature : -20 to 60°C degree
- Operating humidity : 20~90%, non-condensing
- Storage humidity : 5 ~90%, non-condensing
- Operating altitude : 16,000 ft
- Non-operating altitude : 40,000 ft
- Shock : 10G acceleration (11ms duration)
- Vibration : 5~500Hz 1G RMS random vibration

• Regulatory

- Safety : FCC & CE certified
- Environmental : RoHS2 & REACH compliant

• Weight (single console)

- Net : 10.8 kgs / 24 lbs

• Dimensions (single console)

- Product : 441.6 x 480 x 44 mm / 17.4 x 18.9 x 1.73 inch

Console Cable

LCD-A3004

- 6 feet DVI-D console cable (bundle)
- DVI-D + USB, server end
- DVI-D + DB15 (USB KB & MS), console port

 

or

LCD-A1014


- 6 feet VGA console cable (alternative)
- VGA + USB, server end
- DB15 (VGA, USB KB & MS), console port

Keyboard

Sn Sun keyboard integrated with touchpad

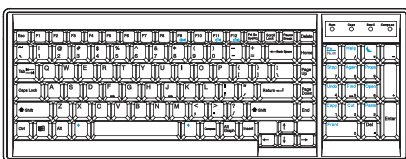

Sb Sun keyboard integrated with trackball

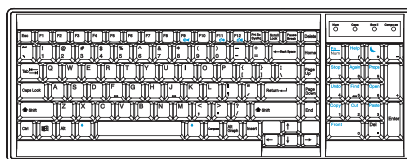

Supporting layouts

America



United States



www.RackmountMart.com

• **Dimensions (with KVM)**

Product : 441.6 x 580 x 44 mm / 17.4 x 22.8 x 1.73 inch

• **Weight**

Net : 11.6 kgs / 25.5 lbs

• **Power Consumption with KVM integration :**

Screen on : Max. 50W

Power saving mode : Max. 29W

• **Casing Color :** Black (RAL 9005)

* For details, please refer to our KVM rear kit user manuals.

Matrix DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-M83IP	-M163IP	-
	1	1	2	-M84IP2	-M164IP2	-
	1	1	0	-M82	-M162	-
	1	2	0	-M83	-M163	-
	1	3	0	-M84	-M164	-

Combo DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	-8KVM2IP	-16KVM2IP	-
	1	1	0	-8KVM2	-16KVM2	-
1	0	0	-8KVM-u	-16KVM-u	-	

Combo DB-15 KVM Cable : LCD-A 3001 / 3002 / 3003 (6-ft, 10-ft, 15-ft)

DVI-D KVM	Local	Remote	IP	12-port	-	-
	1	0	0	-12DVI	-	-

DVI-D KVM Cable : LCD-A 3005 / 3006 (6-ft, 15-ft)

USB Hub DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	-H8KVM2IP	-H16KVM2IP	-
	1	1	0	-H8KVM2	-H16KVM2	-
1	0	0	-H8KVM	-H16KVM	-	

USB KVM Cable : LCD-A 1014 / 1015 / 1016 (6-ft, 10-ft, 15-ft)