

SPECIFICATIONS

Display	
Screen Size	15 Inch
Max. Resolution	1024 x 768 @ 75Hz
Pixel Pitch	0.297 x 0.297mm
Brightness	300cd/m ²
Contrast Ratio	700 : 1
Aspect Ratio	4 : 3
Viewing Angle (H/V)	160° / 160°
Display Color	16.2 Million
Response Time	< 8ms
Video System	NTSC / PAL
Interface	
Video In / Out (BNC Type)	1 In / 1 Out
HDMI In	1 In
S-Video In	0 In
VGA In (15 Pin D-Sub)	1 In
Audio In (RCA Type)	1 In
PC Stereo In	1 In
Transmitter	
Remote Control	N/A
Audio	
Built-in Speakers	Yes (1W x 2)
Features	
Filter Type	2D Comb Filter
LCD Protection Glass	N/A
Multi Language	English, Spanish, French, German, Italian
General	
Outline Dimension (W x H x D)	18.98" x 10.39" x 2.87"
Net Weight	4.3Kg (9.5 lbs)
Material / Color	Electronic galvanized iron / Black
Desk Top Stand	Kick Stand
Consumption: < On	< 25W
	AC100 ~ 240V(50/60Hz)
Electrical Ratings	DC12V / 3A
Operating Temperature	0° ~ 40° C / 32° ~ 104° F
Storage Temperature	-20° ~ 60° C / -4° ~ 140° F
Mounts	
VESA™ Mount Size	100 x 100mm
Wall (optional)	SYWB-5, SYWB-10, SYWB-30, SYWB-31
Ceiling (optional)	SYCMK-01
Form Factor	6U Rack Mounting
Mount Type	Tiltable Rack Mount


Design and specifications are subject to change without notice

TILT CAPABILITY


LCDR6U15-04 has flexible tiltable rack mount capability




INPUT INTERFACE

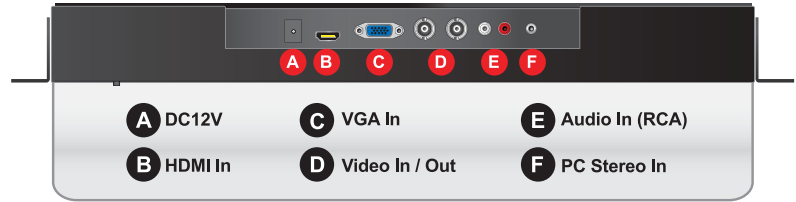

DIMENSIONS

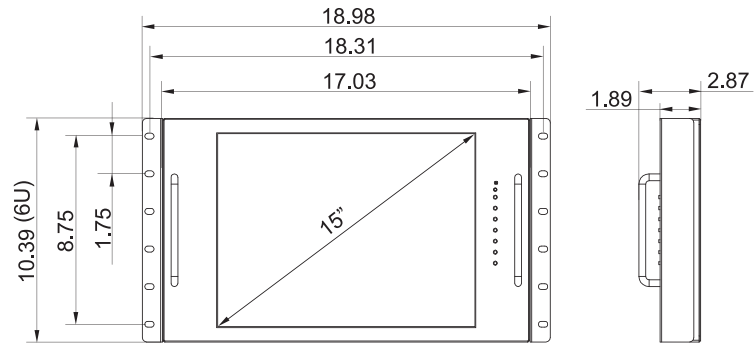

OTHER VIEW

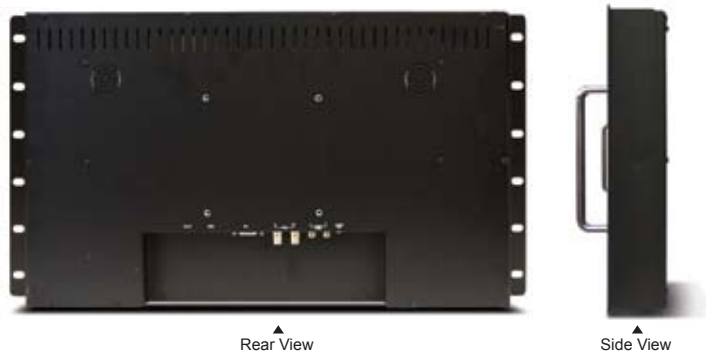

OPTIONAL MOUNTS

