


# LCDR8U17-06 8U Tiltable Rack Mount 17" LCD Display

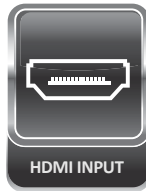

24 X 7 X 365

## FEATURES

- » Industrial Electronic Galvanized Iron Cabinet
- » 1280 x 1024 @ 75Hz Resolution, 250 Nits, 1000:1 Contrast Ratio
- » BNC Video 2 In / 2 Out, S-Video 1 In, HDMI In 1 In, VGA 1 In, Audio 1 In, PC Stereo 1 In
- » 3D Motion Adaptive Deinterlacer / Noise Reduction
- » 1W x 2 Built-In Speakers
- » 8U Rack Mounting Form Factor



# SPECIFICATIONS

Display	
Screen Size	17 Inch
Max. Resolution	1280 x 1024 @ 75Hz
Pixel Pitch	0.264 x 0.264mm
Brightness	250cd/m <sup>2</sup>
Contrast Ratio	1000 : 1
Aspect Ratio	5 : 4
Viewing Angle (H/V)	170° / 160°
Display Color	16.7 Million
Response Time	< 5ms
Video System	NTSC / PAL
Interface	
Video In / Out (BNC Type)	2 In / 2 Out
HDMI In	1 In
S-Video In	1 In
VGA In (15Pin D-Sub)	1 In
Audio In (RCA Type)	1 In
PC Stereo In	1 In
Transmitter	
Remote Control	Yes
Audio	
Built-in Speakers	Yes (1W x 2)
Features	
Filter Type	3D Motion Adaptive De-interlacer
Noise Reduction	Yes
Multi Language	English, Spanish, French, German, Italian
General	
Outline Dimension (W x H x D)	18.98" x 13.90" x 2.87"
Net Weight	5.76Kg (12.7 lbs)
Material / Color	Electronic galvanized iron / Black
Tilt Function	Yes
Consumption: < On	< 30W
Electrical Ratings	AC100 ~ 240V(50/60Hz)
Operating Temperature	0° ~ 40° C / 32° ~ 104° F
Storage Temperature	-20° ~ 60° C / -4° ~ 140° F
Mounts	
VESA™ Mount Size	100 x 100mm
Wall	SYWB-5, SYWB-10, SYWB-30, SYWB-31
Ceiling	SYCMK-01
Form Factor	8U Rack Mounting
Mount Type	Tilttable Rack Mount


\*Design and specifications are subject to change without notice

# TILT CAPABILITY


LCDR8U17-06 has flexible tilttable rack mount capability




# INPUT INTERFACE

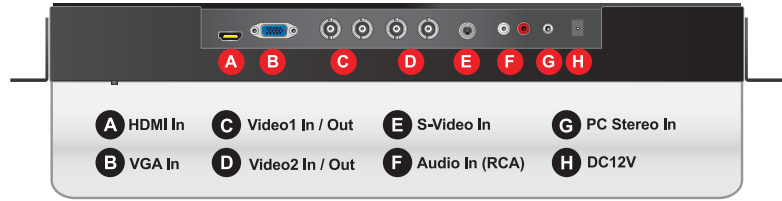

# DIMENSIONS

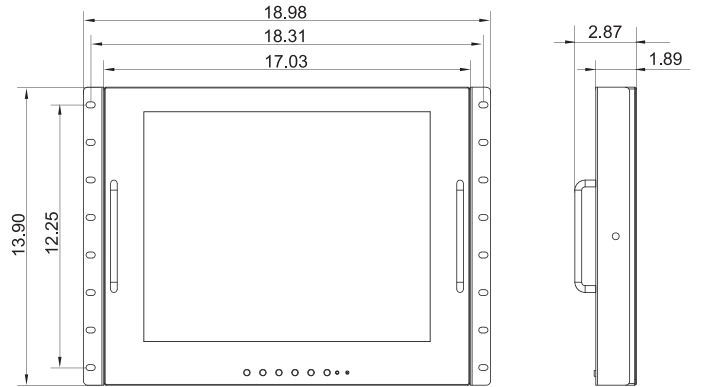

# OTHER VIEW

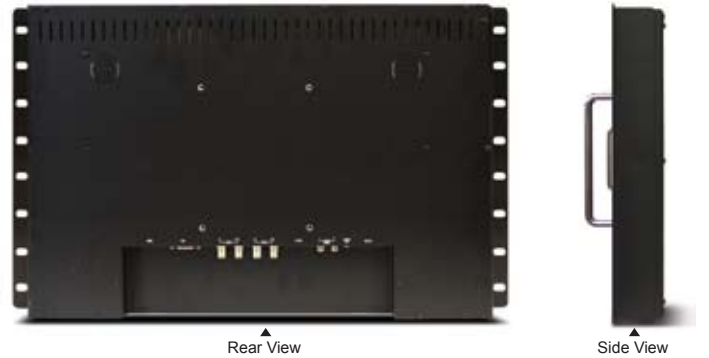

# OPTIONAL MOUNTS

