



www.RackmountMart.com



Benefits

- ▶ 1U 17" LCD console drawer
- ▶ 1920 x 1080 native resolution / 16.7M colors (8-bit)
- ▶ HDMI + VGA video input (speakers excluded)
- ▶ 104-key USB keyboard with either touchpad or trackball
- ▶ Short depth design of 460mm
- ▶ One Man installation design
- ▶ New enhanced aesthetics with molded front handle

Options

- Dual stereo speakers for HDMI
- DP 1.0 + Speakers
- DVI-D + Audio input & output + Speakers
- Composite + Audio IN + Speakers
- 3G / HD / SD-SDI Broadcast-grade input + Speakers
- Front USB hub port for device access
- 2-post rack mounting brackets
- DC power : 12V / 24V / 48V / 110V / 125V / 250V
- SUN Micro keyboard option
- Touchscreen :
Projected Capacitive 10-pt / Resistive 1-pt

Product Specifications

Console Port	
Video input	VGA + HDMI 1.4
KB / MS	USB interface
VGA console 6ft cable	Drawer end : DB-15 + USB type A x 2
or	Server end : DB-15 + USB type A x 2
HDMI console 6ft cable	Drawer end : HDMI + USB type A x 2
	Server end : HDMI + USB type A x 2

LCD Panel	
Panel size (diagonal)	17.3"
Native resolution	1920 x 1080
Brightness (cd/m ²)	300
Contrast ratio (typ.)	1000 : 1
Colors	16.7 M, 8-bit
Viewing angle (L/R/U/D)	85/85/85/85
Response time (ms)	25
Dot pitch (mm)	0.1989
Display area (mm)	381.888H x 214.812V
Surface treatment	Anti-glare, Hard-coating
Surface hardness	3H
Backlight type	LED
MTBF (hrs)	15,000

Physical		
Product (W x D x H)	Single console	442 x 460 x 44 mm 17.4 x 18.1 x 1.73 inch
	Console w/ KVM	442 x 580 x 44 mm 17.4 x 22.8 x 1.73 inch
Net weight	Single console	10.8 kg / 23.8 lb
	Console w/ KVM	11.6 kg / 25.5 lb

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Mounting Distance	
Single console drawer	470 ~ 700 mm 18.5 ~ 27.6 inch
Console w/ KVM drawer	470 ~ 800 mm 18.5 ~ 31.5 inch

Video Option		
Digital	DVI-D	DVI-D single link
	Display port	DP 1.0 / HDCP 1.3
Analog	Composite (BNC)	NTSC & PAL

Audio Option		
Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 14W / Max. 45W
	Power saving mode	Max. 2W / Max. 34W
	Power button off	Max. 1W / Nil

Environment	
Operating temp.	0 to 55°C degree
Storage temp.	-20 to 60°C degree
Operating humidity	10~90%, non-condensing
Storage humidity	5 ~90%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10~300Hz 0.5G RMS random vibration

Compliance	
EMC	FCC, CE & CCC
Safety	c UL us, CE / LVD, UKCA & CCC
Environment	RoHS3 & REACH / WEEE


** Resolution related to LCD specification

2K KVM	IP	Remote	8-port
	0	0	LCD1U17-30-8HD

2K KVM Cable



LCD-A3011 (6 ft)
DVI-D KVM cable




LCD-A3012 (6 ft)
HDMI KVM cable

Resolution: 16:9 - max. 2560 x 1440
Support **: 16:10 - max. 1920 x 1200
4:3 - max. 1600 x 1200

DVI-D KVM	IP	Remote	12-port
	0	0	LCD1U17-30-12DVI

DVI-D USB KVM Cable


Resolution: 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200




LCD-A3005 (6 ft)
LCD-A3006 (15 ft)

Cat6 Matrix KVM	IP	Remote	8-port	16-port	32-port
	1	1	-	LCD1U17-30-MU164IP2	LCD1U17-30-MU324IP2
2	1	-	LCD1U17-30-MU163IP	LCD1U17-30-MU323IP	
0	1	-	LCD1U17-30-MU162	LCD1U17-30-MU322	
0	2	-	LCD1U17-30-MU163	LCD1U17-30-MU323	
0	3	-	LCD1U17-30-MU164	LCD1U17-30-MU324	


Cat6 KVM Dongle




LCD-A2006
USB-C dongle




LCD-A2005
DP - USB dongle



LCD-A2004
HDMI - USB dongle



LCD-A2003
DVI - USB dongle




LCD-A2001
VGA - USB dongle

Resolution: 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200


Cat6 Combo KVM	IP	Remote	8-port	16-port	32-port
	1	0	LCD1U17-30-U8KVM2IP	LCD1U17-30-U16KVM2IP	LCD1U17-30-U32KVM2IP
0	1	LCD1U17-30-U8KVM2	LCD1U17-30-U16KVM2	LCD1U17-30-U32KVM2	
0	0	LCD1U17-30-U8KVM	LCD1U17-30-U16KVM	LCD1U17-30-U32KVM	

DB-15 Combo KVM	IP	Remote	8-port	16-port
	1	0	LCD1U17-30-8KVM2IP	LCD1U17-30-16KVM2IP
0	1	LCD1U17-30-8KVM2	LCD1U17-30-16KVM2	
0	0	LCD1U17-30-8KVM-u	LCD1U17-30-16KVM-u	


DB-15 VGA USB KVM Cable



LCD-A1014 (6 ft)



LCD-A1015 (10 ft)





LCD-A1016 (15 ft)


Resolution: 16:10 - max. 1920 x 1200
Support **: 16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

DB-15 USB Hub KVM	IP	Remote	8-port	16-port
	1	0	LCD1U17-30-H8KVM2IP	LCD1U17-30-H16KVM2IP
0	1	LCD1U17-30-H8KVM2	LCD1U17-30-H16KVM2	
0	0	LCD1U17-30-H8KVM	LCD1U17-30-H16KVM	

IP Console







 


High Performance KVM Access Over IP

Connector :	RJ45
User management :	1 x active user, 15-user login
Network protocol :	DHCP / BOOTP / DNS
Security :	TLS 1.3, AES, LDAP, Active Directory (AD), HTTP(s)
Browser :	Chrome, Firefox, Edge, etc.
Resolution :	16:9 - max. 1920 x 1080 / 16:10 - max. 1920 x 1200 / 4:3 - max. 1600 x 1200








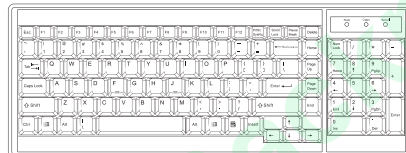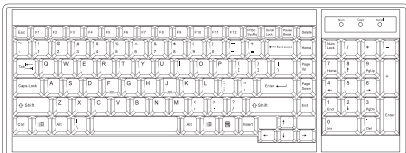

Standard Keyboard

N keyboard integrated with touchpad

 B keyboard integrated with trackball



Supporting layouts

America		U.S.
EMEA	     	U.K. Germany France Russia Spain Italy
Asia	 	Japan Korea

Keyboard Options

* US layout only

Sn SUN keyboard with touchpad

Sb SUN keyboard with trackball

