



↑  
(USB Port for device access)




## Features


- 1U 17.3 inch widescreen LCD Console Drawer
- HDMI 2.0 & Display Port 1.4 - Single port model
- 4K resolution 3840 x 2160
- Support 1920 x 1080 & 1920 x 1200 resolution
- Front 1xUSB, Rear 2xUSB 2.0 Type A, Sharing USB peripheral Device for computer (ex, flash disk, hard driver, KB/Mouse)
- 104-key keyboard with touch pad mouse.
- 8 ports HDMI 2.0 input (Option)
- Port selection via push buttons or hotkey - 8-Port KVM model
- USB 2.0 Keyboard & Mouse
- Self-locking and auto release rails for ultra convenience.
- Build in 2x 2 watts speakers

## Options

- 48V, 24V or 12V DC Power

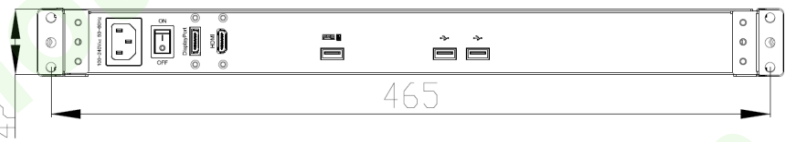

Rear of LCD1U17-47

 

Rear of LCD1U17-47-8HD

| Part No.                                 |                  | LCD1U17-47   | LCD1U17-47-8HD               |
|--|------------------|--|------------------------------|
| Direct no. of Computers                  |                  | 1  | 8                            |
| KVM Connectors                           |                  | HDMI 2.0, Display port 1.4, USB  | 8 x HDMI 2.0                 |
| LCD                                      | Size             | 17.3"  |                              |
|  | Backlight        | LED  |                              |
|  | Resolution       | 4K resolution 3840 x 2160  |                              |
|  | Max.color        | 16.7M  |                              |
|  | Luminance        | 400cd/m2   |                              |
|  | View Angel (H/V) | 178 / 178  |                              |
|  | Contrast Ratio   | 1000 : 1   |                              |
| USB HUB                                  |                  | 1x Front , 2x Rear USB 2.0 Type A for peripheral USB devices (For 8-port KVM, only 1 x Rear USB) |                              |
| Touch Screen                             |                  | option ( Single-port only. Driver is needed)   |                              |
| KB/Mouse Emulation                       |                  | USB  |                              |
| Rack Depth ( front rails to rear rails ) |                  | 380mm to 620mm ( short brackets )<br>560mm to 762mm ( long brackets )                            | 450mm to 600mm               |
| Power                                    |                  | 100-240V AC 50/60Hz via IEC Type power cord  |                              |
| Environment                              |                  | Operation temp: 0 to 50℃   |                              |
|  |                  | Storage temp: -20 to 60℃   |                              |
|  |                  | Humidity: 10% - 90%, non-condensing  |                              |
|  |                  | Shock: 10G acceleration ( 11ms duration)<br>Vibration: 17 to 500Hz 1G PTP                        |                              |
| Physical Dimensions / Net Weights        |                  | 443x42x406mm (WxHxD) /10.5KG   | 443x42x457.2mm (WxHxD) /11KG |
| Accessories                              |                  | KVM cables are optional  |                              |