



1000 cd/m² brightness

Benefits

- ▶ 1U 19" FHD LCD console drawer
- ▶ 1920 x 1080 native resolution / 16.7M colors / 1000 cd/m² brightness
- ▶ HDMI 1.4 + VGA video input (speakers excluded)
- ▶ 104-key USB keyboard with either touchpad or trackball
- ▶ Short depth design of 460mm
- ▶ One Man installation design
- ▶ Enhanced aesthetics with new molded front panel and 2-point lock

Options

- Dual stereo speakers for HDMI
- DP 1.0 + Speakers
- DVI-D + Audio input & output + Speakers
- Composite + Audio IN + Speakers
- 3G / HD / SD-SDI Broadcast-grade input + Speakers
- Front USB hub port for device access
- DC power : 12V / 24V / 48V / 125V / 250V
- SUN Micro keyboard option

Product Specifications

Console Port	
Video input	HDMI 1.4 + VGA
KB / MS	USB interface
VGA console 6ft cable	Drawer end : DB-15 + USB type A x 2
or	Server end : DB-15 + USB type A x 2
HDMI console 6ft cable	Drawer end : HDMI + USB type A x 2
	Server end : HDMI + USB type A x 2

Video Option		
Digital	DVI-D	DVI-D single link
	Display port	DP 1.0 / HDCP 1.3
Analog	Composite (BNC)	NTSC & PAL

LCD Panel	
Panel size (diagonal)	18.5"
Native resolution	1920 x 1080
Brightness (cd/m ²)	1000
Contrast ratio (typ.)	1000 : 1
Colors	16.7 M
Viewing angle (L/R/U/D)	89/89/89/89
Response time (ms)	20
Dot pitch (mm)	0.213
Display area (mm)	408.98H x 230.04V
Surface treatment	Anti-glare, Hard-coating
Surface hardness	3H
Backlight type	LED
MTBF (hrs)	50,000

Audio Option		
Input	Connector	3.5mm stereo jack
	Impedance / Power level	30kΩ / 750mV
Output	Connector	3.5mm stereo jack
	Resistance / Power level	30kΩ / 2.8V
Speaker	Dual stereo	2W x 2

Power		
Input	Auto-sensing 100 to 240VAC, 50 / 60Hz	
Consumption (console / KVM)	Screen on	Max. 40W / Max. 71W
	Power saving mode	Max. 2W / Max. 34W
	Power button off	Max. 1W / Nil

Physical		
Product (W x D x H)	Single console	442 x 460 x 44 mm 17.4 x 18.1 x 1.73 inch
	Console w/ KVM	442 x 580 x 44 mm 17.4 x 22.8 x 1.73 inch
Net weight	Single console	11.5 kg / 25.3 lb
	Console w/ KVM	12.5 kg / 28 lb

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

Environment	
Operating temp.	-20 to 70°C degree
Storage temp.	-20 to 70°C degree
Operating humidity	10 ~ 90%, non-condensing
Storage humidity	5 ~ 95%, non-condensing
Operating altitude	16,000 ft
Non-operating altitude	40,000 ft
Shock	10G acceleration (11ms duration)
Vibration	10-300Hz 0.5G RMS random vibration

Mounting Distance	
Single console drawer	470 ~ 700 mm 18.5 ~ 27.6 inch
Console w/ KVM drawer	470 ~ 800 mm 18.5 ~ 31.5 inch

Compliance	
EMC	FCC & CE
Safety	CE / LVD & UKCA
Environment	REACH & RoHS3 / MEEE

** Resolution related to LCD specification

2K KVM	IP	Remote	8-port
	0	0	-8HD


2K KVM Cable



Resolution Support **: 16:9 - max. 2560 x 1440
16:10 - max. 1920 x 1200
4:3 - max. 1600 x 1200

DVI-D KVM	IP	Remote	12-port
	0	0	-12DVI


DVI-D USB KVM Cable



Resolution Support **: 16:10 - max. 1920 x 1200
16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

Cat6 Matrix KVM	IP	Remote	8-port	16-port	32-port
	1	1	-	-MU164IP2	-MU324IP2
	2	1	-	-MU163IP	-MU323IP
	0	1	-	-MU162	-MU322
	0	2	-	-MU163	-MU323
	0	3	-	-MU164	-MU324

Cat6 KVM Dongle

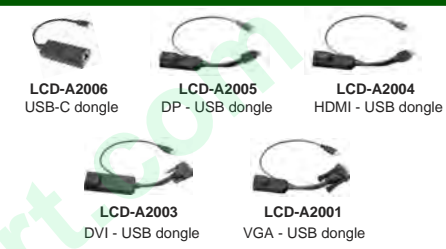


Resolution Support **: 16:10 - max. 1920 x 1200
16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

Cat6 Combo KVM	IP	Remote	8-port	16-port	32-port
	1	0	-U8KVM2IP	-U16KVM2IP	-U32KVM2IP
	0	1	-U8KVM2	-U16KVM2	-U32KVM2
	0	0	-U8KVM	-U16KVM	-U32KVM

DB-15 Combo KVM	IP	Remote	8-port	16-port
	1	0	-8KVM2IP	-16KVM2IP
	0	1	-8KVM2	-16KVM2
	0	0	-8KVM-u	-16KVM-u


DB-15 VGA USB KVM Cable



Resolution Support **: 16:10 - max. 1920 x 1200
16:9 - max. 1920 x 1080
4:3 - max. 1600 x 1200

DB-15 USB Hub KVM	IP	Remote	8-port	16-port
	1	0	-H8KVM2IP	-H16KVM2IP
	0	1	-H8KVM2	-H16KVM2
	0	0	-H8KVM	-H16KVM

IP Console



 
High Performance KVM Access Over IP

Connector : RJ45
 User management : 1 x active user, 15-user login
 Network protocol : DHCP / BOOTP / DNS
 Security : TLS 1.3, AES, LDAP, Active Directory (AD), HTTP(s)
 Browser : Chrome, Firefox, Edge, etc.
 Resolution : 16:9 - max. 1920 x 1080 / 16:10 - max. 1920 x 1200 / 4:3 - max. 1600 x 1200

Standard Keyboard

N keyboard integrated with touchpad

B keyboard integrated with trackball



Supporting layouts

America U.S.

EMEA U.K. Germany France Russia Spain Italy

Asia Japan Korea

Keyboard Options

* US layout only

Sn SUN keyboard with touchpad

Sb SUN keyboard with trackball

