


## Basic Rack PDU

### Overview

**Outlets.** The Rack PDU has twenty (20) IEC-320-C13 outlets, and four (4) IEC-320-C19 outlets.

**Power cord.** The 10-foot (3.05-meter) power cord terminates with an IEC-320-C20 connector.

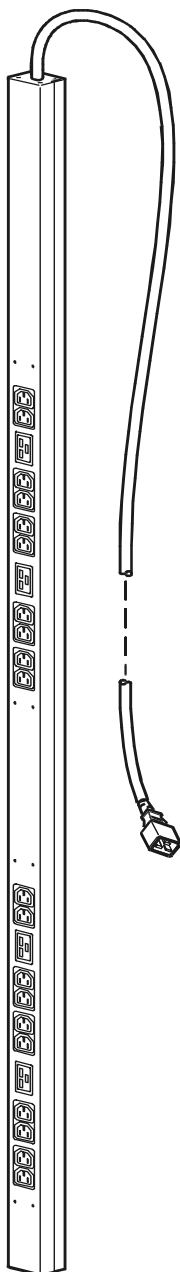

**RA5024-C-16A-C20**

# Specifications

---

## Electrical

---

Input connector	IEC-320-C20 plug
Output connectors	(20) IEC-320-C13 (4) IEC-320-C19 outlets
Nominal input voltage	230 VAC
Acceptable input voltage	± 10% of nominal voltage
Input frequency	47–63 Hz
Cord length	10 ft (3.05 m)

---

## Physical

---

Dimensions (H × W × D)	63.75 × 2.19 × 1.73 in (161.92 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	9.5 lb (4.3 kg)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

---

## Compliance

---

Safety verification	VDE 0805, CE, EN 60950, IEC 60950
---------------------	--------------------------------------

---



**Synergy Global Technology Inc**  
[www.RackmountMart.com](http://www.RackmountMart.com)