



Synergy Global Technology Inc


www.RackmountMart.com

Basic Rack PDU

Overview

Outlets. The Rack PDU has twenty (20) IEC-320-C13 outlet, and four (4) IEC-320-C19 outlets.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA L6-20 connector.

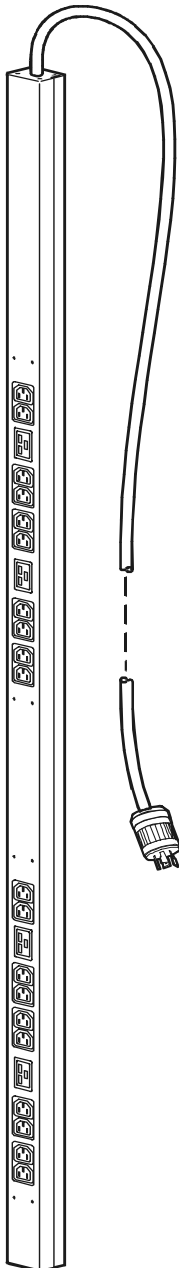

RA5024-C-20A-L620

Specifications

Electrical

| | |
|--------------------------|---|
| Input connector | NEMA L6-20 plug |
| Output connectors | (20) IEC-320-C13 (4) IEC-320-C19 outlets |
| Nominal input voltage | 200 – 240 VAC |
| Acceptable input voltage | ± 10% of nominal voltage |
| Input frequency | 47– 63 Hz |

Physical

| | |
|------------------------------------|--|
| Dimensions (H × W × D) | 63.75 × 2.19 × 1.73 in (161.92 × 5.56 × 4.39 cm) |
| Shipping dimensions (H × W × D) | 84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm) |
| Weight | 10 lb (4.54 kg) |

Environmental

| | |
|----------------------------------|------------------------------|
| Maximum elevation (above MSL) | |
| Operating | 15,000 ft (4500 m) |
| Storage | 50,000 ft (15 000 m) |
| Temperature | |
| Operating | –5 to 45° C (23 to 115° F) |
| Storage | –25 to 65° C (–13 to 149° F) |
| Humidity | |
| Operating | 5 – 95% RH non-condensing |
| Storage | 5 – 95% RH non-condensing |

Compliance

| | |
|---------------------|---------------------|
| Safety verification | UL/cUL 60950 Listed |
|---------------------|---------------------|



Synergy Global Technology Inc

www.RackmountMart.com