




Synergy Global Technology Inc

www. RackmountMart.com

Basic Rack PDU

Outlets. The Rack PDU has ten (10) IEC-320-C13 outlets.

Power cord. The 12-foot (3.65-meter) power cord terminates with a NEMA L6-30 connector.

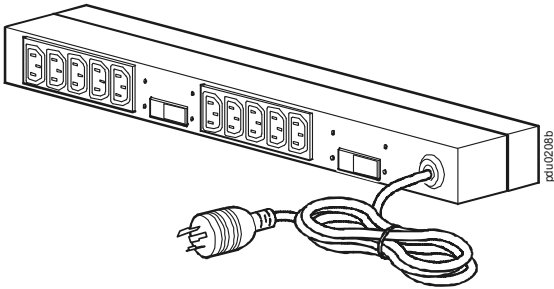

RA5110-C13-30A-L630

Specifications

Electrical

| | |
|-----------------------------------|-----------------------------------|
| Input connector | NEMA L6-30 plug |
| Output connectors | 10 – IEC-320-C13 outlets |
| Nominal input voltage | 200–240 VAC |
| Acceptable input voltage | ± 10% of normal voltage |
| Input frequency | 50/60 Hz |
| Maximum total current draw | 30 A (24 A UL (C-UL) derated) |
| Overcurrent protection (internal) | (2) 20 A, 2-pole circuit breakers |

Physical

| | |
|------------------------------------|---|
| Size (H × W × D) | 17.5 × 1.7 × 3.03 in (44.5 × 4.4 × 7.69 cm) |
| Shipping Dimensions (H × W × D) | 6.75 × 19.00 × 6.875 in (17.14 × 48.26 × 17.46 cm) |
| Weight | 5.6 lb (2.5 kg) |

Environmental

| | |
|-----------------------|------------------------------|
| Elevation (above MSL) | |
| Operating | 0 – 10,000 ft (0 – 3000 m) |
| Storage | 0 – 50,000 ft (0 – 15 000 m) |
| Temperature | |
| Operating | –5 to 45° C (23 to 115° F) |
| Storage | –25 to 65° C (–13 to 149° F) |
| Humidity | |
| Operating | 5 – 95% RH non-condensing |
| Storage | 5 – 95% RH non-condensing |

Compliance

| | |
|---------------------|------------------|
| Safety verification | UL (C-UL) listed |
|---------------------|------------------|



Synergy Global Technology Inc

www.RackmountMart.com