




**Synergy Global Technology Inc**

[www.RackmountMart.com](http://www.RackmountMart.com)

## Basic Rack PDU

**Outlets.** The Rack PDU has thirty (30) IEC-320-C13 outlets (15A maximum) and six (6) IEC-320-C19 outlets (16A maximum). APC power cord AP9877 (1.98 m; 6.5 ft) is available for purchase for use with C19 outlets.

**Input power cord.** The 0.91-m (3-ft) power cord terminates with a CS8365C connector.

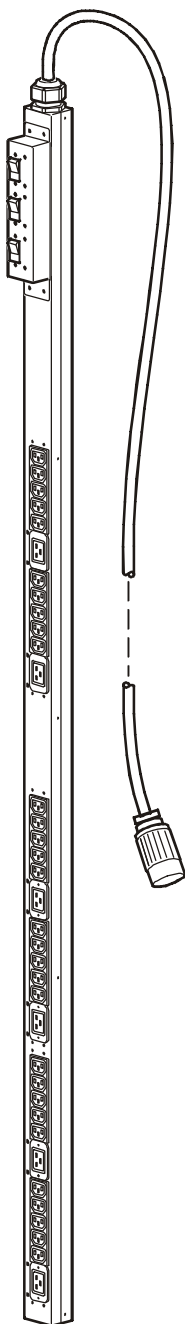

**RAH5036-C-35A-CS**

# Specifications

---

## Electrical

---

Input connector	CS8365C plug
Output connectors	(30) IEC-320-C13 (6) IEC-320-C19 outlets
Cord length	0.91 m (3 ft)
Nominal input voltage	200 - 240 VAC, 3-phase
Acceptable input voltage	+6%, -10% of nominal voltage
Input frequency	50/60 Hz
Output current	15A/C13, 16A/C19; 16A/bank
Overload protection	
Internal	(3) 20-A 2-pole breakers
External	(1) 50-A 3-pole breaker

---

## Physical

---

Dimensions (H × W × D)	1778×56×45 mm (70.00×2.20×1.75 in)
<i>(Including breaker box)</i>	1778×56×89 mm (70.00×2.20×3.50 in <sup>†</sup> )
Shipping dimensions (H × W × D)	211 × 15 × 127 mm (83.00×6.00×5.00 in)
Weight	6.93 kg (15.28 lb)

---

## Environmental

---

Maximum elevation (above MSL)	
Operating	3000 m (10,000 ft)
Storage	15 000 m (50,000 ft)
Temperature	
Operating	-5 to 45° C (23 to 115° F)
Storage	-25 to 65° C (-13 to 149° F)
Humidity	
Operating	5 – 95% RH non-condensing
Storage	5 – 95% RH non-condensing

---

## Regulatory Approvals

---

Product safety	UL, cUL Listed
----------------	----------------

---

<sup>†</sup>The depth with the breaker box (89 mm; 35.0 in) extends for only a part (190 mm; 7.50 in) of the height of the unit.