




Synergy Global Technology Inc

www.RackmountMart.com

Basic Rack PDU

Outlets. The Rack PDU has forty-two (42) NEMA 5-20 outlets.

Power cord. The 3-foot (0.91-meter) power cord terminates with a NEMA L21-20 connector.

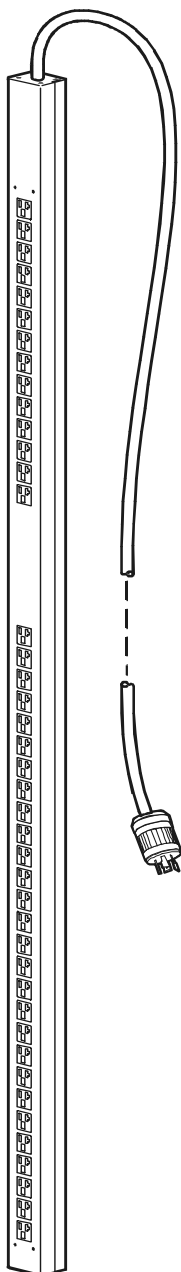

RAH5042-520-20A-L212

Specifications

Electrical

Input connector	NEMA L21-20 plug
Output connectors	(42) NEMA 5-20 outlets
Nominal input voltage	120 VAC, 3-phase
Acceptable input voltage	± 10% of nominal voltage
Input frequency	47–63 Hz

Physical

Dimensions (H × W × D)	70.00 × 2.19 × 1.73 in (177.80 × 5.56 × 4.39 cm)
Shipping dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	12 lb (5.44 kg)

Environmental

Maximum elevation (above MSL)	
Operating	15,000 ft (4500 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5–95% RH non-condensing
Storage	5–95% RH non-condensing

Compliance

Safety verification	UL/cUL 60950 Listed
---------------------	---------------------



Synergy Global Technology Inc

www.RackmountMart.com