



Synergy Global Technology Inc


www.RackmountMart.com

Basic Rack PDU

Overview

Outlets. The Rack PDU has thirty-six (36) IEC-309-C13 outlets and six (6) IEC-309-C19 outlets.

Power cord. The 3-ft (0.91-m) power cord terminates with an IEC-309 20-A plug.

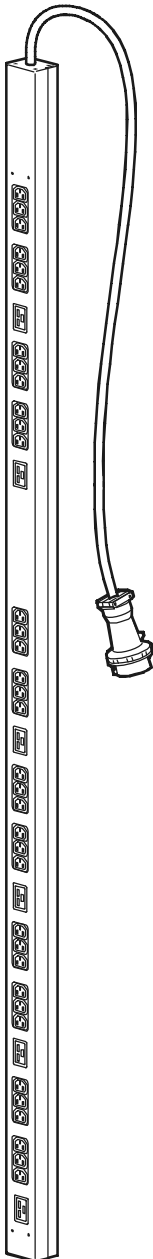

RAH5042-C-20A-IEC

Specifications

Electrical

Input connection	IEC-309, 20 A
Input power	11.0 kVA
Acceptable input voltage	220–240/380–415 VAC
Maximum input current (phase)	20 A
Derated input current (phase)	16 A
Input frequency	50/60 Hz
Output voltage	240 VAC (line to neutral)
Output connections	(36) IEC-309-C13 (6) IEC-309-C19
Cord length	3.00 ft (0.91 m)
Maximum output current (outlet)	10 A–IEC-309-C13 16 A–IEC-309-C19
Maximum output current (phase)	16 A

Physical

Dimensions (H x W x D)	70.00 x 2.19 x 1.73 in (177.80 x 5.56 x 4.39 cm)
Shipping dimensions (H x W x D)	84.00 x 6.00 x 5.00 in (213.36 x 15.24 x 12.7 cm)
Weight	12.37 lb (5.61 kg)

Environmental

Maximum elevation (above MSL)	
Operating	10,000 ft (3000 m)
Storage	50,000 ft (15 000 m)
Temperature	
Operating	23 to 115°F (–5 to 45°C)
Storage	–13 to 149°F (–25 to 65°C)
Humidity	
Operating	5–95% RH, non-condensing
Storage	5–95% RH, non-condensing

Compliance

Safety verification	UL/cUL: UL60950-1
---------------------	-------------------



Synergy Global Technology Inc

www.RackmountMart.com