



Synergy Global Technology Inc


www.RackmountMart.com

Basic Rack PDU

Overview

Outlets. The Rack PDU has thirty-six (36) IEC 320-C13 outlets and 6 (6) IEC 320-C19 outlets.

Power cord. The 3-foot (0.91-meter) power cord terminates with a NEMA L21-20 connector.

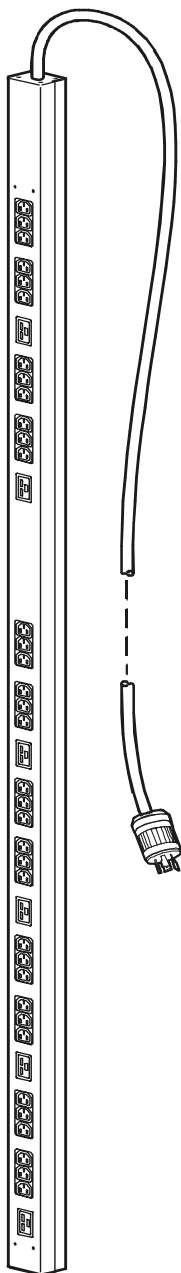

RAH5042-C-20A-L212

Specifications

Electrical

| | |
|--------------------------|--|
| Input connector | NEMA L21-20 plug |
| Output connectors | (36) IEC 320-C13 outlets (6) IEC 32-C19 outlets |
| Nominal input voltage | 120/208 VAC 3-phase |
| Acceptable input voltage | ± 10% of normal voltage |
| Input frequency | 47–63 Hz |

Physical

| | |
|------------------------------------|--|
| (H × W × D) | 70.00×2.19×1.73 in (177.80×5.56×4.39 cm) |
| Shipping dimensions (H × W × D) | 84.00×6.00×5.00 in (213.36×15.24×12.7 cm) |
| Weight | 12 lb (5.44 kg) |

Environmental

| | |
|----------------------------------|------------------------------|
| Maximum elevation (above MSL) | |
| Operating | 15 000 ft (4500 m) |
| Storage | 50 000 ft (15 000 m) |
| Temperature | |
| Operating | –5 to 45° C (23 to 115° F) |
| Storage | –25 to 65° C (–13 to 149° F) |
| Humidity | |
| Operating | 5–95% RH non-condensing |
| Storage | 5–95% RH non-condensing |

Compliance

| | |
|---------------------|---------------|
| Safety verification | UL, cUL 60950 |
|---------------------|---------------|



Synergy Global Technology Inc

www.RackmountMart.com