


3-Phase 400V 63A basic PDU : C13 x 24 + C19 x 6

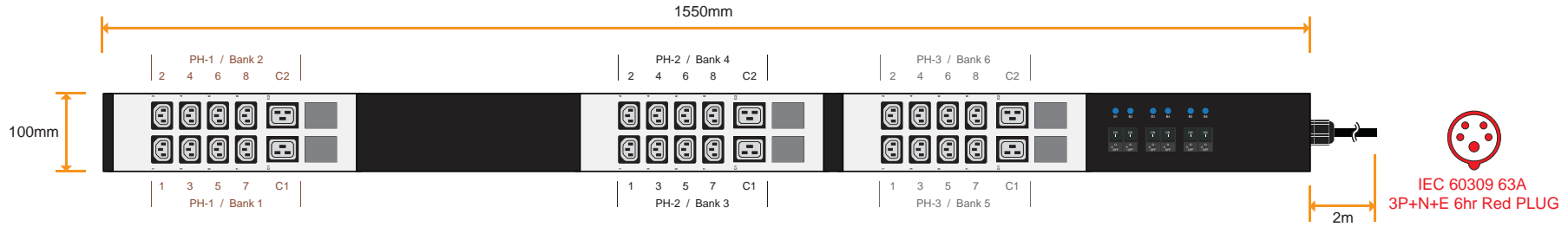

| 63A model : | Fuse | MCB |
|-----------------------------|------|-----|
| VP24C13/6C19-63A-CR_EN/2B-2 | - | 6 |

- Input Rating : 63A, 400V
- Inlet : 63A IEC60309 3P+N+E 6hr Red plug
- Cordset : 5-wire 2 meter 10.0mm sq. H07RN-F cordset
- Protection : 30A single pole hydraulic MCB x 6
- Bank Details :
 - PH-1** < **Bank 1** > Output 30A max. C 13 # 1-7 (odd) + C 19 # C 1
 - < **Bank 2** > Output 30A max. C 13 # 2-8 (even) + C 19 # C 2
 - PH-2** < **Bank 3** > Output 30A max. C 13 # 1-7 (odd) + C 19 # C 1
 - < **Bank 4** > Output 30A max. C 13 # 2-8 (even) + C 19 # C 2
 - PH-3** < **Bank 5** > Output 30A max. C 13 # 1-7 (odd) + C 19 # C 1
 - < **Bank 6** > Output 30A max. C 13 # 2-8 (even) + C 19 # C 2

Three phase basic PDU

Outlet : 10A Rated IEC320 C13 x 24
16A Rated IEC320 C19 x 6



The company reserves the right to modify product specifications without prior notice and assumes no responsibility for any error which may appear in this publication.

Copyright 2015 Synergy Global Technology Inc. All rights reserved.

EMC Compliance : FCC & CE certified
Safety Compliance : CE / LVD certified
Environment Compliance : RoHS2 & REACH

Operating Temperature : -5 to 60 °C
Storage Temperature : -25 to 65 °C
Operating Altitude : 0 to 2,000 m
Storage Altitude : 0 to 15,000 m
Humidity : 8 to 95% RH, non-condensing

Dimension : 100 (W) x 70 (D) x 1550 (H) mm
Material : Steel
Color : White (outlet bracket)
Black (chassis)