




# LCD1U17-016/1U19-016/1U20-013 Rackmount Quad LCD Drawer

New




## Diagram

Unit : mm

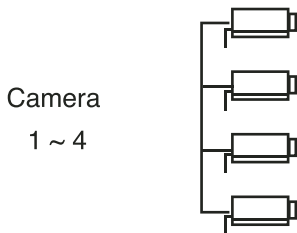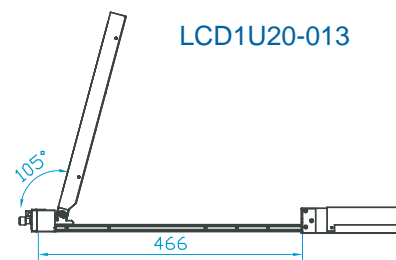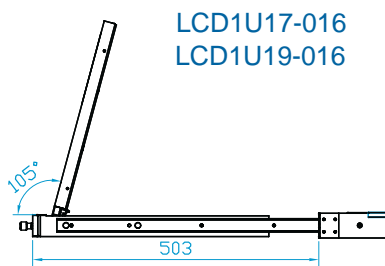

Camera  
1 ~ 4

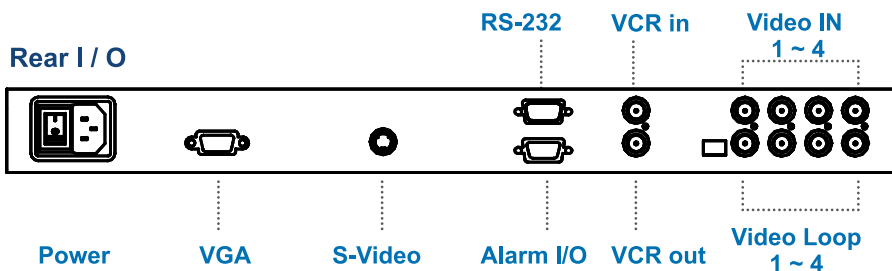

## Front QD membrane button



- **DC** 12V, 24V and 48V DC Power options

## Drawer Features & Options

- 1U LCD drawer with either 4 : 3, 17", 19" or 20" LCD

### LCD Drawer Benefits

- ▶ Built-in Quad Display
- ▶ Ideal for CCTV security & industrial control
- ▶ "One Man" installation slides included except 20" LCD model
- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed

**Monitor** Grade A 17", 19" industrial TFT LCD panel  
 Grade A 20" industrial TFT LCD panel

- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 20" 1600 x 1200 LCD with 300 nit brightness and 800:1 contrast ratio typical

### Ordering Information

17" LCD Series

19" LCD Series

20" LCD Series

Model	LCD1U17-016	LCD1U19-016	LCDR1U20-013
-------	-------------	-------------	--------------

### Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-016	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	12 kg / 26 lbs
LCD1U19-016	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	13 kg / 29 lbs
LCD1U20-013	442 x 650 x 44 mm 17.4 x 25.6 x 1.73 inch	14 kg / 31 lbs