

DESCRIPTION



45 RMU Open Rack, 4-Post, Adjustable Depth Steel Frame

Compatible with vertical cable managers: CM17-T-45 (metal) & CM21 (plastic, 2 sections) Series

Height	Width	Depth	Color	Weight	Capacity
84 in	24 in	24-36 in	Black	61 LB	1322 LB

FEATURES

- 4-Post Rack
- Holes for #12-24 screws
- Highly functional and stylish
- Adjustable depth

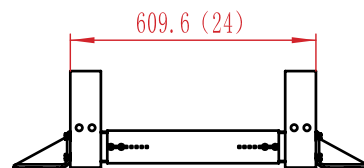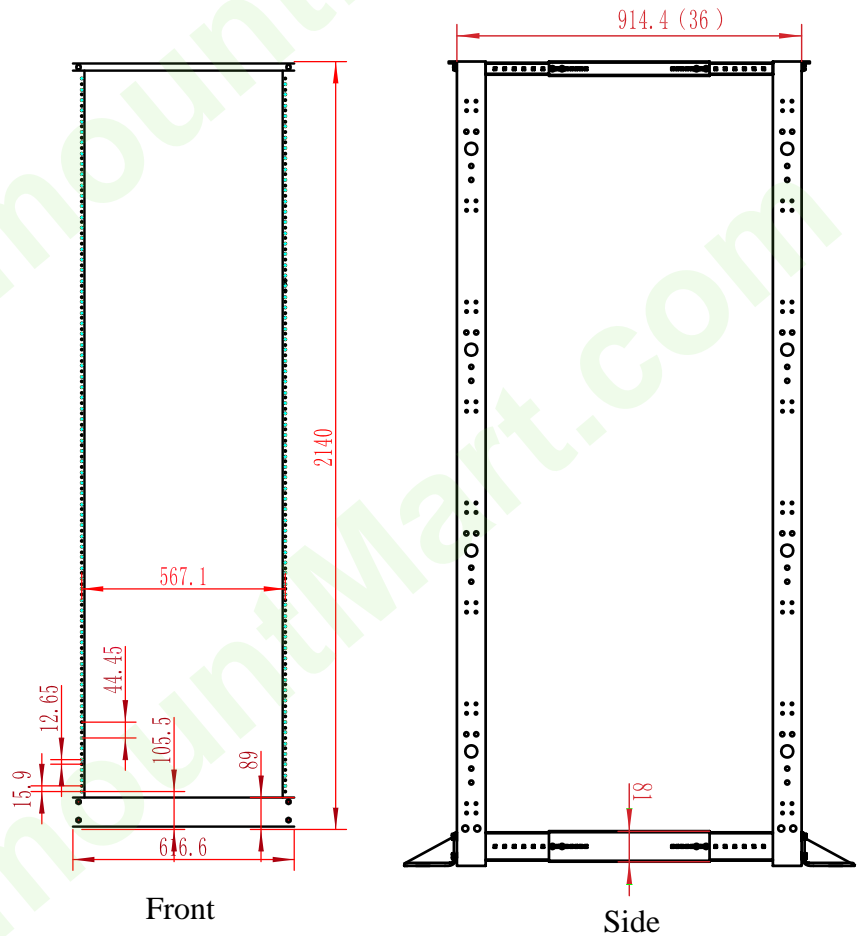

What's in the Box:

- (1) #12-24 screws 40 pcs,
- (2) # 12-24 washers 40 pcs,
- (3) 3/8"×1" UNF black bolts + nuts 24pcs both,
- (4) 3/8" flat washers 40pcs
- (5) Assembly Instruction