


LCD1U-15-02/17-03-8KVM

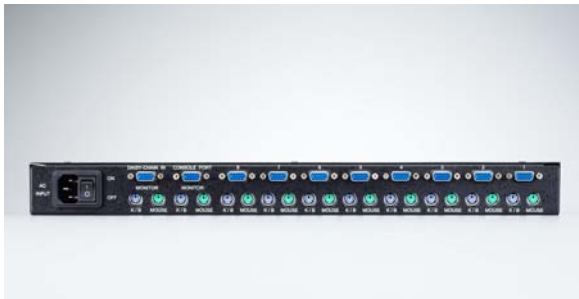


Features :

- meets EIA310c & IEC-3 specifications
- One set built-in Keyboard, touch pad, monitor and 8 ports KVM switch
- heavy-duty steel
- With high brightness TFT LCD Panel
- **Anti-glare tempered glass for added protection to the LCD screen**
- Membrane keyboard in 105 keys, with touch pad
- Built-in rail self-locking device
- Support DOS, Windows OS, Netware, SCO Unix, HP Unix, Linux
- Easy PC selection via ON Screen Display Manual, Push buttons, Hot keys
- Support eight characters password protection and search PC server name
- Auto scan mode for monitoring PCs
- using standard keyboard, mouse, VGA cable

Specification :

- 482.5mm(W) 44.5mm(H) 580mm(D)
- 15" TFT LCD, 1024*768, 250 nits,
- 17" TFT LCD, 1280*1024, 300 nits
- Backlight MTBF: 50,000 hours under 25±5 °C
- 8 ports, PC type KVM switch
- Daisy chain max level up to 8 levels
- Max PC Connection up to 120 set with extra KVM Switch box
- FCC, CE approval

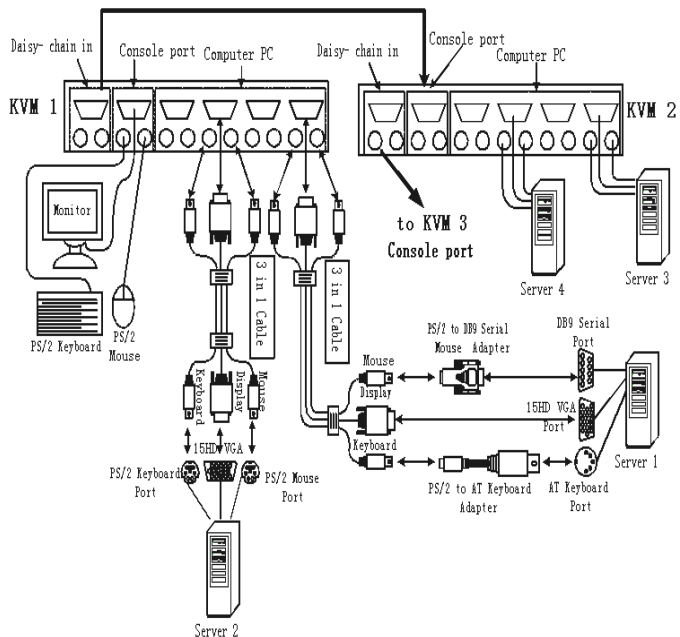

		KVM Cable
		Included