




PS/2 DB-15 KVM Benefits

- ▶ PS/2 DB-15 KVM with 8 ports in 1U
- ▶ Mix PS/2, USB & SUN with Multi-Platform switch capability
- ▶ Low cost reliable PS/2 based server management
- ▶ No software or drivers required
- ▶ Easy & quick installation

Switch Features & Options

- Multi lingual on screen display menu
- Advanced user profiles and configurable OSD hot key combinations
- DC power options : 12V / 24V / 48V / 110 ~ 125V

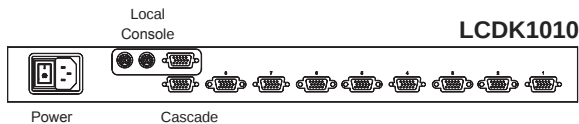


Ordering Information

Console	Local	Remote	IP	8-port
	1	0	0	LCDK1010

KVM Specification

■ KVM Port Number of ports: 8 Connector: DB-15 combo connector Connectivity: PS/2 3-in-1 KVM cable, up to 6, 10 & 15 feet		■ Power Input: Auto sensing 100 to 240VAC, 50 / 60 Hz Option DC: 12V / 24V / 48V / 110 ~ 125V DC input Consumption: Max. 12W	
■ Local Console Graphic Connector: 1 x DB-15 VGA Input device: 2 x PS/2 for keyboard & mouse Resolution support : 4:3 - max. 1600 x 1200 16:10 - max. 1920 x 1200		■ Regulatory Safety: FCC & CE certified Environment: RoHS2 & REACH compliant	
■ Management OSD: English Hotkey: Scroll-Lock Security: Password enable & disable PC Selection: Front button, OSD menu & hotkey		■ Environmental Operating temperature : 0 to 55°C degree Storage temperature : -20 to 60°C degree Operating humidity : 20~90%, non-condensing Storage humidity : 5 ~90%, non-condensing Operating altitude : 16,000 ft Non-operating altitude : 40,000 ft Shock : 10G acceleration (11ms duration) Vibration : 5~500Hz 1G RMS random vibration	
■ Expansion: Up to 64 servers by 8-level cascade		■ Product Information Dimension (W x D x H) : 443 x 171 x 44 mm / 17.4 x 6.7 x 1.73 inch Net weight : 3 kg / 6.5 lb	
■ Compatibility Hardware : HP / IBM / Dell PC, Server and Blade Server SUN / Mac OS Support : Windows / Linux / Unix / Mac OS			

KVM port connection

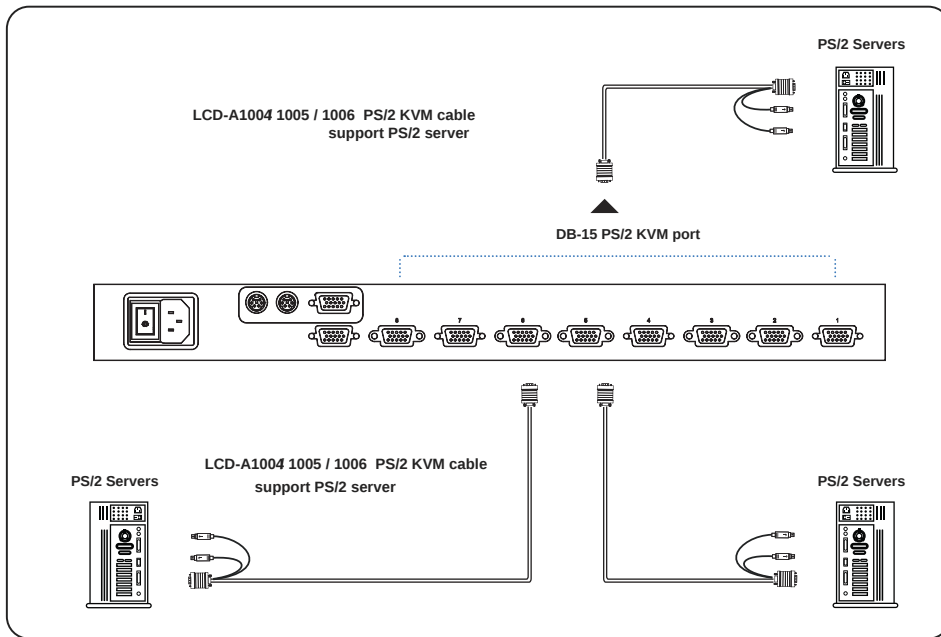**LCD-A1004 1005 / 1006**

- 6 / 10 / 15 ft PS/2 KVM cable
- Support PS/2 server

 For detailed product specifications and options, please download the user manual from product page

KVM Cascade

- Cascade up to 8 levels, 64 servers
- Cascading multiple KVM with LCD-A1019 cascade cable.

