

ID-26Pw-LED 26" Widescreen LCD w/ LED-backlit Panel Display



Universal open frame mounting



Display Benefits

- ▶ 26" widescreen LCD supports **Full HD** 1080p resolution
- ▶ PIP & Picture by Picture viewing efficiency
- ▶ Green LED-backlit panel technology
- ▶ Rugged construction against external impact
- ▶ Standard with HDMI, DVI-D, VGA, S-Video, RCA, Audio & remote controller

Options

- 3G / HD / SD-**SDI** Broadcast-grade input
- **MC** Multi-display control solution
- 26" Touchscreen : Resistive, Capacitive
- 48V or 24VDC power
- MIL-type or lockable connector
- TV - Analog

Basic I/O



Specifications

LCD Panel

Manufacturer :	LG
Size (diagonal) :	26" Widescreen TFT
Max resolution :	1920 x 1080
Brightness (cd/m2) :	350
Backlight :	LED
Colors :	16.7 M
Contrast ratio (typ) :	1000 : 1
Viewing angle (H/V) :	178° x 178°
Active area (mm) :	576 x 324
MTBF (hrs) :	50,000
Signal input :	HDMI / DVI-D / VGA / S-Video / RCA

Weight

Net :	10 kgs (22 lbs)
-------	-------------------

Mounting :

Wall-mount / VESA mount

Environmental

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5~90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5~500Hz 1G RMS random vibration

Casing Color :

Dark grey (RAL 7037)

Regulatory :

FCC, CE

Power


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 200 Watt, Standby 20 Watt

Dimensions


Product :	673.7 x 52 x 421.6 mm / 26.5 x 2 x 16.6 inch
-----------	--

Diagrams (mm)

Front View

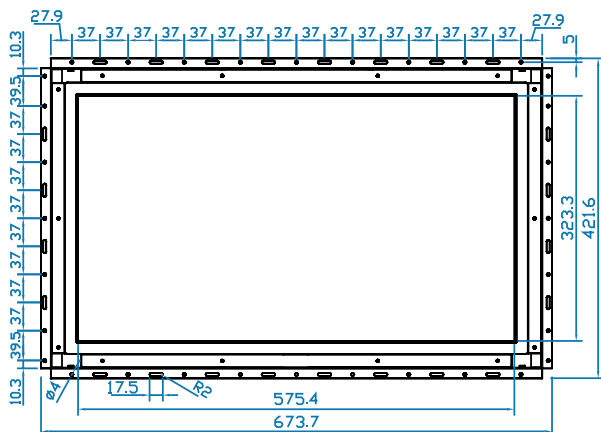

Side View

 

Rear View

