



Single Console

Drawer Features & Display Benefits

- ▶ 1U dual slide 17" or 19" LCD console drawer
- ▶ 104-key keyboard with touchpad
- ▶ Enhanced aesthetics with new molded front panel and two point lock
- ▶ Combo interface either PS/2 or USB for single console drawer

Options

- S-Video + Composite (BNC) or Audio input
- HDMI or DVI-D (either one)
- DC power : 12V / 24V / 48V / 110 ~ 125V



Specifications

• **LCD Panel**

Manufacturer :	AUO	AUO
Size (diagonal) :	17" TFT	19" TFT
Max resolution :	1280 x 1024	1280 x 1024
Brightness (cd/m2) :	250	250
Backlight :	CCFL	LED
Colors :	16.7 M	16.7 M
Contrast ratio (typ) :	1000 : 1	1000 : 1
Viewing angle (H/V) :	160° x 160°	170° x 160°
Active area (mm) :	338 x 270	376 x 301
MTBF (hrs) :	50,000	30,000
Signal input :	VGA	VGA

• **Speaker :** Built-in Dual Stereo Speakers (option) 2W x 2

• **Power Input :** Auto-sensing 100 to 240VAC, 50 / 60Hz

• **Power Consumption (single console)**

Screen on :	Max. 25W
Power saving mode :	Max. 4W
Power button on :	Max. 1W

• **Environmental**

Operating temperature :	0 to 55°C degree
Storage temperature :	-20 to 60°C degree
Operating humidity :	20~90%, non-condensing
Storage humidity :	5 ~90%, non-condensing
Operating altitude :	16,000 ft
Non-operating altitude :	40,000 ft
Shock :	10G acceleration (11ms duration)
Vibration :	5~500Hz 1G RMS random vibration

• **Casing Color :** Black (RAL 9005)

• **Regulatory**

Safety :	cUL, FCC & CE certified
Environmental :	RoHS2 & REACH compliant

• **Weight (single console) Net**

LCD1U17-20 :	12.6 kgs / 27.7 lbs
LCD1U19-22 :	13.2 kgs / 29 lbs

• **Dimensions (single console)**

Product : 441.6 x 650 x 44 mm / 17.4 x 25.6 x 1.73 inch

 

Console Cable

LCD-A3001







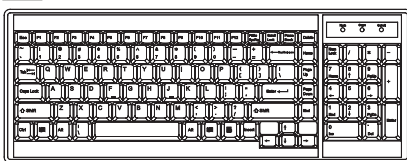









- 6 feet Combo KVM cable (bundle)
- VGA + USB or PS/2, server end
- DB15 (VGA, USB KB & MS), console port

Keyboard

n keyboard integrated with touchpad



Supporting layouts

America	 United States				
EMEA	 United Kingdom	 Germany	 France	 Spain	 Norway
	 Italy	 Russia	 Switzerland	 Netherlands	 Portugal
Asia	 China	 Japan	 Korea	 Arabia	 Turkey



• Dimensions (with KVM)

Product : 441.6 x 650 x 44 mm / 17.4 x 25.6 x 1.73 inch

• Weight (Net)

LCD1U17-20 : 13.6 kgs
(29.9 lbs)

LCD1U19-22 : 14.2 kgs
(31.2 lbs)

• Power Consumption with KVM integration :

Sreen on : Max. 55W

Power saving mode : Max. 34W

• Casing Color : Black (RAL 9005)

* For details, please refer to our KVM rear kit user manuals.

Matrix Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-	-MU163IP	-MU323IP
	1	1	2	-	-MU164IP2	-MU324IP2
	1	1	0	-	-MU162	-MU322
	1	2	0	-	-MU163	-MU323
	1	3	0	-	-MU164	-MU324

Combo Cat6 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	-U8KVM2IP	-U16KVM2IP	-U32KVM2IP
	1	1	0	-U8KVM2	-U16KVM2	-U32KVM2
1	0	0	-U8KVM	-U16KVM	-U32KVM	

Cat6 KVM Dongle : LCD-A2001 (VGA-USB) / LCD-A2002 (VGA-PS/2) / LCD-A2003 (DVI-USB)

Matrix DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-M83IP	-M163IP	-
	1	1	2	-M84IP2	-M164IP2	-
	1	1	0	-M82	-M162	-
	1	2	0	-M83	-M163	-
1	3	0	-M84	-M164	-	

Combo DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	-8KVM2IP	-16KVM2IP	-
	1	1	0	-8KVM2	-16KVM2	-
1	0	0	-8KVM-u	-16KVM-u	-	

Combo DB-15 KVM Cable : LCD-A3001 / 3002 / 3003 (6, 10 or 15 ft)

DVI-D KVM	Local	Remote	IP	12-port	-	-
	1	0	0	-12DVI	-	-

DVI-D KVM Cable : LCD-A3005 / 3006 (6 or 15 ft)