



Single Console

1920 x 1200
WUXGA



Drawer Features & Display Benefits

- ▶ 1U dual slide 17" widescreen LCD console drawer
- ▶ 1920 x 1200 native **WUXGA** Ultra high resolution
- ▶ Support **Full HD** with 1080p resolution
- ▶ 104-key keyboard with touchpad
- ▶ SUN Micro or MAC keyboard options available
- ▶ Enhanced aesthetics with new molded front panel and two point lock

Options

- 3G / HD / SD-SDI Broadcast-grade input
- S-Video + Composite (BNC), HDMI or Audio input
- DC power : 12V / 24V / 48V / 110 ~ 125V

Specifications

• **LCD Panel**

- Size (diagonal) : 17.1" widescreen TFT
- Max resolution : 1920 x 1200
- Brightness (cd/m2) : 210
- Backlight : LED
- Colors : 16.7 M, 8-bit
- Contrast ratio (typ) : 600 : 1
- Viewing angle (H/V) : 130° x 110°
- Active area (mm) : 367 x 230
- MTBF (hrs) : 20,000
- Signal input : VGA or DVI-D

• **Speaker :**

Built-in Dual Stereo Speakers
2W x 2

• **Casing Color :**

Black (RAL 9005)

• **Power Input :**

Auto-sensing 100 to 240VAC,
50 / 60Hz

• **Power Consumption (single console)**

- Screen on : Max. 34W
- Power saving mode : Max. 4W
- Power button on : Max. 1W

• **Environmental**

- Operating temperature : 0 to 55°C degree
- Storage temperature : -20 to 60°C degree
- Operating humidity : 20~90%, non-condensing
- Storage humidity : 5 ~90%, non-condensing
- Operating altitude : 16,000 ft
- Non-operating altitude : 40,000 ft
- Shock : 10G acceleration (11ms duration)
- Vibration : 5~500Hz 1G RMS random vibration

• **Regulatory**

- Safety : FCC & CE certified
- Environmental : RoHS2 & REACH compliant

• **Weight (single console)**

- Net : 12 kgs / 26.4 lbs

• **Dimensions (single console)**

- Product : 441.6 x 650 x 44 mm / 17.4 x 25.6 x 1.73 inch

Console Cable

LCD-A3004

- 6 feet DVI-D console cable (bundle)
- DVI-D + USB, server end
- DVI-D + DB15 (USB KB & MS), console port


or

LCD-A1014

- 6 feet VGA console cable (alternative)
- VGA + USB, server end
- DB15 (VGA, USB KB & MS), console port

Standard Keyboard

n keyboard integrated with touchpad

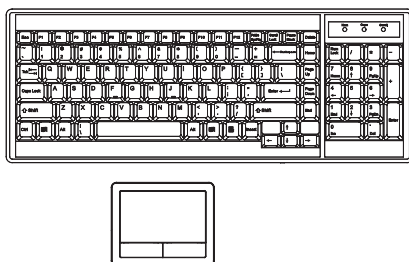

Supporting layouts

America	United States				
EMEA	United Kingdom	Germany	France	Spain	Norway
	Italy	Russia	Switzerland	Netherlands	Portugal
Asia	China	Japan	Korea	Arabia	Turkey

Keyboard Options

* US layout only

Mn Mac keyboard with touchpad



Sn Sun keyboard with touchpad





• **Dimensions (with KVM)**

Product : 441.6 x 650 x 44 mm / 17.4 x 25.6 x 1.73 inch

• **Weight**

Net : 13 kgs / 28.6 lbs

• **Power Consumption with KVM integration :**

Screen on : Max. 59W

Power saving mode : Max. 29W

• **Casing Color :** Black (RAL 9005)

* For details, please refer to our KVM rear kit user manuals.

Matrix DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	1	1	-M83IP	-M163IP	-
	1	1	2	-M84IP2	-M164IP2	-
	1	1	0	-M82	-M162	-
	1	2	0	-M83	-M163	-
	1	3	0	-M84	-M164	-

Combo DB-15 KVM	Local	Remote	IP	8-port	16-port	32-port
	1	0	1	-8KVM2IP	-16KVM2IP	-
	1	1	0	-8KVM2	-16KVM2	-
	1	0	0	-8KVM-u	-16KVM-u	-

Combo DB-15 KVM Cable : LCD-A 3001 / 3002 / 3003 (6-ft, 10-ft, 15-ft)

DVI-D KVM	Local	Remote	IP	12-port	-	-
	1	0	0	-12DVI	-	-

DVI-D KVM Cable : LCD-A 3005 / 3006 (6-ft, 15-ft)