



6mm aluminum front bezel with optional
NEMA 4 / IP65
 front protection



Display Benefits

- ▶ 15" LCD with resolution 1024 x 768
- ▶ Rugged construction against external impact
- ▶ Protective 3mm glass

 
Options

- S-Video + BNC & Audio
- 15" Touchscreen : Capacitive, Resistive
- 48V, 24V or 12VDC power
- TV - Analog

Standard I/O



BNC-SPK upgrade I/O



Specifications

• **LCD Panel**

Manufacturer :	AUO
Size (diagonal) :	15" TFT
Max resolution :	1024 x 768
Brightness (cd/m2) :	250
Backlight :	CCFL
Colors :	16.2 M
Contrast ratio (typ) :	700 : 1
Viewing angle (H/V) :	150° x 135°
Active area (mm) :	304 x 228
MTBF (hrs) :	30,000
Signal input :	VGA

• **Weight**

Net / Gross : 3.5 kgs (7.7 lbs)

• **Mounting :**

Panel mount / VESA mount

• **Environmental**

Operating :	0 to 50°C Degree
Storage :	-5 to 60°C Degree
Relative humidity :	5-90%, non-condensing
Shock :	10G acceleration (11 ms duration)
Vibration :	5-500Hz 1G RMS random vibration

• **Casing Color :**

Black front panel (RAL 9005)
 Dark grey rear case (RAL 7037)

• **Regulatory :**

FCC, CE

• **Power**


Input :	Auto-sensing 100 to 240VAC, 50 / 60Hz
Consumption :	Max. 40 Watt, Standby 5 Watt

• **Dimensions**


Product : 407 x 59 x 314 mm / 16 x 2.3 x 12.3 inch

Diagrams (mm)

Front View

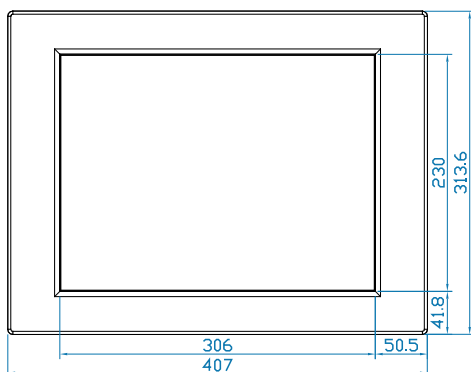

Side View

 

Rear View

