




Ultra short depth
400mm / 15.7"

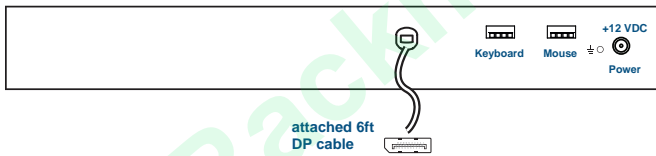

attached 6ft
DP cable

Benefits

- ▶ 1U 17" 4K LCD console drawer
- ▶ 3840 x 2160@60Hz native resolution / 16.7M colors (8-bit)
- ▶ 2560 x 1440@60Hz QHD resolution support
- ▶ 1920 x 1080 & 1920 x 1200 resolution support
- ▶ Display port 1.2 video input / USB KB/MS
- ▶ Ideal for open rack / short depth rack
- ▶ 104-key keyboard with either touchpad or trackball
- ▶ Built-in dual stereo speakers
- ▶ One Man installation design
- ▶ Enhanced aesthetics with new molded front panel and 2-point lock

Options

- HDMI 2.0 video input * (**HDMI**)
- 3G / HD / SD-SDI Broadcast-grade input (**SDI**)
- DC power : 12V / 24V / 48V / 110V / 125V / 250V
- MAC or SUN Micro keyboard options available
- Touchscreen :
Projected Capacitive 10-pt / Resistive 1-pt

* with 2 x USB cable for keyboard & mouse

Product Specifications

| Console Port | |
|--------------------------------------|------------------|
| Video input attached 6ft DP cable | Display port 1.2 |
| KB / MS bundled 6ft USB cable x 2 | USB type A |

| LCD Panel | |
|----------------------------------|-------------------|
| Panel size (diagonal) | 17.3" |
| Native resolution | 3840 x 2160@60Hz |
| Brightness (cd/m ²) | 400 |
| Contrast ratio (typ) | 1000 : 1 |
| Colors | 16.7 M, 8-bit |
| Viewing angle (L/R/U/D) | 89/89/89/89 |
| Response time (ms) | 16 |
| Dot pitch (mm) | 0.0995 |
| Display area (mm) | 382.12H x 214.94V |
| Surface treatment | Anti-glare |
| Surface hardness | 3H |
| Backlight type | LED |
| MTBF (hrs) | 15,000 |

| Physical | | |
|--------------------------|----------------|---|
| Product (W x D x H) | Single console | 442 x 400 x 44 mm 17.4 x 15.7 x 1.73 inch |
| | Console w/ KVM | 442 x 490 x 44 mm 17.4 x 19.29 x 1.73 inch |
| Net weight | Single console | 8.7 kg / 19.1 lb |
| | Console w/ KVM | 9.5 kg / 20.9 lb |

* All dimensions stated are subject to change if options are selected / integrated to base model part codes

| Mounting Distance | |
|-----------------------|----------------------------------|
| Single console drawer | 410 ~ 640 mm 16.1 ~ 25.2 inch |
| Console w/ KVM drawer | 410 ~ 800 mm 16.1 ~ 31.5 inch |


| Video Option | | |
|--------------|------|---------------------|
| Digital | HDMI | HDMI 2.0 / HDCP 2.2 |

| Power | | |
|--------------------------------|---------------------------------------|---------------------|
| Input | Auto-sensing 100 to 240VAC, 50 / 60Hz | |
| Consumption (console / KVM) | Screen on | Max. 21W / Max. 38W |
| | Power saving mode | Max. 2W / Max. 18W |
| | Power button off | Max. 1W / Nil |

| Environment | |
|------------------------|------------------------------------|
| Operating temp. | 0 to 55°C degree |
| Storage temp. | -20 to 60°C degree |
| Operating humidity | 10~90%, non-condensing |
| Storage humidity | 5 ~90%, non-condensing |
| Operating altitude | 16,000 ft |
| Non-operating altitude | 40,000 ft |
| Shock | 10G acceleration (11ms duration) |
| Vibration | 10~300Hz 0.5G RMS random vibration |

| Compliance | |
|-------------|----------------------|
| EMC | FCC & CE |
| Safety | CE / LVD & UKCA |
| Environment | REACH & RoHS3 / WEEE |

| | | | |
|----------------|----|--------|----------------|
| 4K 60Hz KVM | IP | Remote | 8-port |
| | 0 | 0 | LCD1U17-41-8HD |

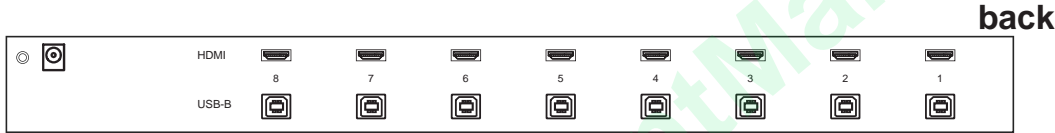

** Resolution related to LCD specification

4K KVM Cable


LCD-A3009 (6 ft)
DP KVM cable

LCD-A3008 (6 ft)
HDMI KVM cable


Resolution 16:9 - max. 3840 x 2160
Support **: 16:10 - max. 1920 x 1200
4:3 - max. 1600 x 1200

Standard Keyboard

N keyboard integrated with touchpad

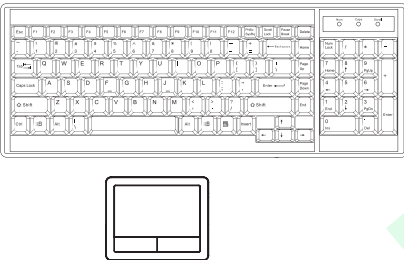

B keyboard integrated with trackball

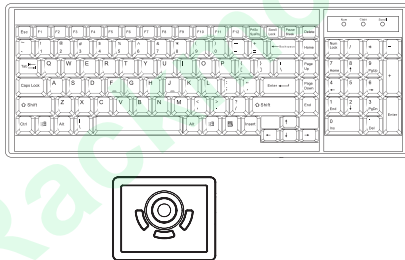

Supporting layouts

- America U.S.

- EMEA U.K. Germany France Russia Spain Italy

- Asia Japan Korea

Keyboard Options

* US layout only

Mn Mac keyboard with touchpad



Sn SUN keyboard with touchpad

Mb Mac keyboard with trackball

Sb SUN keyboard with trackball

