



Synergy Global Technology Inc


www.RackmountMart.com

Basic Rack PDU

Overview

Outlets. The Rack PDU has twenty IEC-320-C13 outlets, and four IEC-320-C19 outlets.

Power cord. The 10-foot (3.05-meter) power cord terminates with a NEMA L6-30 connector.

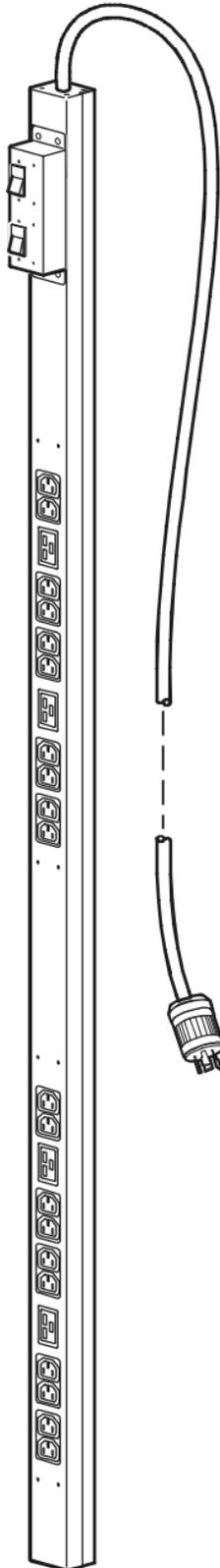

RA5024-C-30A-L630

Specifications

Electrical

Input connector	NEMA L6-30 plug
Output connectors	20 – IEC-320-C13, 4 – IEC 320-C19 outlets
Nominal input voltage	200 – 240 VAC
Acceptable input voltage	± 10% of normal voltage
Input frequency	50/60 Hz
Maximum total current draw	30 A (24 A (UL(C-UL) derated)
Overcurrent protection (internal)	(2) 20-A, 2-pole circuit breakers

Physical

Size (H × W × D)	63.75 × 2.19 × 1.73 in (161.92 × 5.56 × 4.39 cm)
Shipping Dimensions (H × W × D)	84.00 × 6.00 × 5.00 in (213.36 × 15.24 × 12.7 cm)
Weight	12.25 lb (5.56 kg)

Environmental

Elevation (above MSL)	
Operating	0 – 10,000 ft (0 – 3000 m)
Storage	0 – 50,000 ft (0 – 15 000 m)
Temperature	
Operating	–5 to 45° C (23 to 115° F)
Storage	–25 to 65° C (–13 to 149° F)
Humidity	
Operating	5 – 95% RH non-condensing
Storage	5 – 95% RH non-condensing

Compliance

Safety verification	UL (C-UL) listed, PSE
---------------------	-----------------------
