


# ID-06P 6.5" Open Frame LCD Panel

## Dimension Drawings (mm)

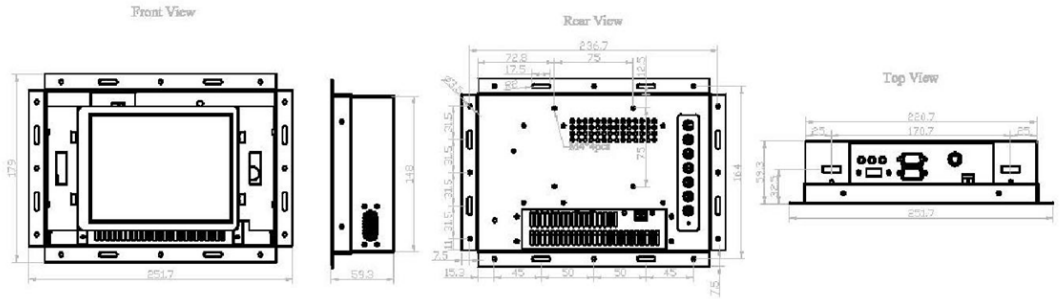

<h3 style="text-align: center;">Applications</h3> <ul style="list-style-type: none"> <li>- Industrial process control</li> <li>- Point of sales / Kiosk</li> <li>- Security / Surveillance</li> <li>- Touchscreen display panel</li> </ul>	<h3 style="text-align: center;">Options</h3> <ul style="list-style-type: none"> <li>- Touchscreen</li> <li>- S-Video, RCA &amp; BNC input</li> <li>- DC power input ( 12 / 24 / 48 VDC )</li> <li>- Audio input with speaker</li> <li>- TV tuner with remote controller</li> <li>- Standard remote controller for AV, VGA input</li> </ul>	<h3 style="text-align: center;">Design features</h3> <ul style="list-style-type: none"> <li>- Industrial open frame kit</li> <li>- OSD control keys to optimize the display</li> <li>- Universal mounting for various applications</li> <li>- Modularized design for flexible integration</li> </ul>
--	--	--

## Specifications

LCD Panel	
Panel Grading	GradeA Industrial TFT LCD panel
Panel Size (in.)	6.5"
Optimum Resolution	640 x 480
Display Color	262K
Brightness-nits (cd/m <sup>2</sup> )	400
Contrast Ratio	600 : 1
Pixel Pitch (mm)	0.203 x 0.203
Viewing Angle (L/R/U/D)	60 / 60 / 40 / 55
OSD Control	Brightness, Contrast, Phase & Clock, Color, H & V position, Auto-tune & Recall
Connector(s)	D-Sub 15 pin VGA analog
LCD Panel MTBF (hrs)	50,000
Power	110~220VAC via AC adapter
Mounting	VESA-mount, Panel-mount Wall-mount & Bracket mount
Dimensions (mm)	251.7 x 59.3 x 179 mm (W x D x H)

Operating Temperature	0° to 50° C
Storage Temperature	-5° to 60° C
Humidity	5~90%, non-condensing
Shock	10G peak acceleration (11ms duration)
Vibration	5-500Hz, 1G RMS random vibration

## Ordering information

Model no.	Description
ID-06P	6.5" open frame LCD panel with VGA input
ID-06P-AV	6.5" open frame LCD with VGA, S-Video+RCA input
ID-06PBNC	6.5" open frame LCD with VGA, S-Video+BNC input
ID-06PDC12	6.5" open frame LCD with VGA input, 12V DC input
ID-06PDC24	6.5" open frame LCD with VGA input, 24V DC input
ID-06PDC48	6.5" open frame LCD with VGA input, 48V DC input
ID-06P-TV	6.5" open frame LCD with TV tuner & Remote Controller
ID-06P-RM	6.5" open frame LCD with Remote Controller
ID-06P-SPK	6.5" open frame LCD with Audio Input
ID-06P-TRS	Add Resistive Touch screen & serial controller
ID-06P-TRB	Add Resistive Touch screen & USB controller
ID-06P-TCS	Add Capacitive Touch screen & serial controller
ID-06P-TCB	Add Capacitive Touch screen & USB controller