


ID-19Dw 19" Widescreen Stylish Front Aluminum Cover LCD Panel

Dimension Drawings (mm)

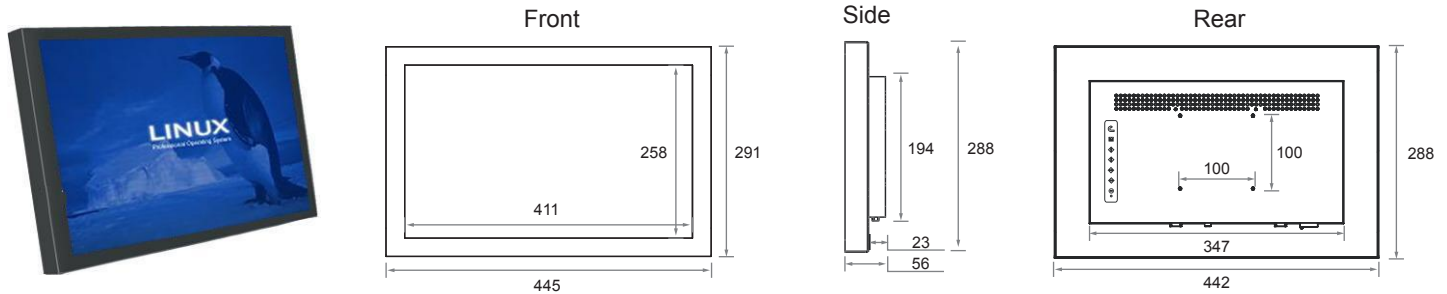

Applications

- Industrial process control
- Point of sales / Kiosk
- Security / Surveillance
- Flight information display

Options

- TV tuner
- BNC, DVI input
- Remote controller
- Audio input with speaker

Design features

- 1.2mm aluminum front cover
- OSD control keys to optimize the display
- Built-in VGA & video input (S-Video & RCA)

Specifications

LCD Panel

SAMSUNG

Panel Grading	Class A TFT LCD panel
Panel Size (in.)	Wide 19" (16 : 10)
Optimum Resolution	1440 x 900
Display Color	16.7M
Brightness-nits (cd/m ²)	300
Contrast Ratio	1000 : 1
Pixel Pitch (mm)	0.284 x 0.284
Viewing Angle (L/R/U/D)	80 / 80 / 80 / 80
OSD Control	Brightness, Contrast, Phase & Clock, Color, H & V position, Auto-tune & Recall
Connector(s)	D-Sub 15 pin VGA analog
LCD Panel MTBF (hrs)	50,000
Power	100~240VAC via AC adapter
Mounting	VESA-mount, Optional OEM mounting design
Dimensions (mm)	445 x 56 x 291 (W x D x H)

Operating Temperature	0° to 50° C
Storage Temperature	-5° to 60° C
Humidity	5~90%, non-condensing
Shock	10G peak acceleration (11ms duration)
Vibration	5-500Hz, 1G RMS random vibration

Ordering information

Model no.	Description
ID-19Dw	Wide 19" stylish front aluminum cover LCD panel with VGA, S-Video + RCA input
ID-19DwBNC	Wide 19" stylish front aluminum cover LCD panel with VGA, S-Video + RCA, BNC input
ID-19DwDVI	Wide 19" stylish front aluminum cover LCD panel with VGA, S-Video + RCA, DVI input