


ID-26Aw 26" Widescreen Front Aluminum LCD Panel

Dimension Drawings (mm)

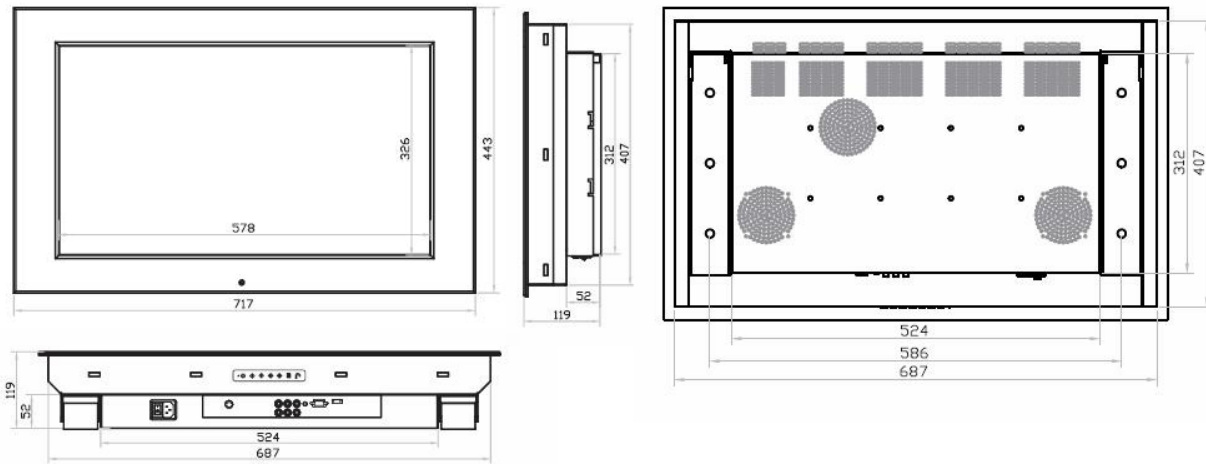

Applications

- Industrial process control
- Point of sales / Kiosk
- Security / Surveillance
- Flight Information display panel

Options

- TV tuner
- NEMA4 / IP65 2mm Protective Glass

Design features

- OSD control keys & remote controller to optimize the display
- Support Picture in Picture (PIP)
- Built-in VGA & HDMI input
- Built-in video input (Component, S-Video & RCA)
- Built-in audio input with speaker

Specifications

LCD Panel

Panel Grading

Panel Size (in.)

Optimum Resolution

Display Color

Brightness-nits (cd/m²)

Contrast Ratio

Pixel Pitch (mm)

Viewing Angle (L/R/U/D)

OSD Control

Connector(s)

LCD Panel MTBF (hrs)

Power

Mounting

Dimensions (mm)



Class A TFT LCD panel

Wide 26" (16 : 9)

1366 x 768

16.7M

450

1500 : 1

0.421 x 0.421

89 / 89 / 89 / 89

Brightness, Contrast, Phase & Clock, Color,
H & V position, Auto-tune & Recall

D-Sub 15 pin VGA analog

50,000

100~240VAC via AC adapter

VESA-mount, Wall-mount, Mounting bracket
and Optional OEM mounting design

717 x 119 x 443 (W x D x H)

Operating Temperature

0° to 50° C

Storage Temperature

-5° to 60° C

Humidity

5~90%, non-condensing

Shock

10G peak acceleration
(11ms duration)

Vibration

5-500Hz, 1G RMS random vibration

Ordering information

Model no.	Description
ID-26Aw	Wide 26" front aluminum LCD panel with VGA, HDMI, Component, S-Video & RCA input, audio input with speaker
ID-26AwTV	Wide 26" front aluminum LCD panel with VGA, HDMI, Component, S-Video & RCA input, TV tuner, audio input with speaker
-IP65	Add NEMA4 / IP65 Protective Glass

www.rackmountmart.com
email : sales@rackmountmart.com

SYNERGY GLOBAL TECHNOLOGY INC 1-888-865-6888