
 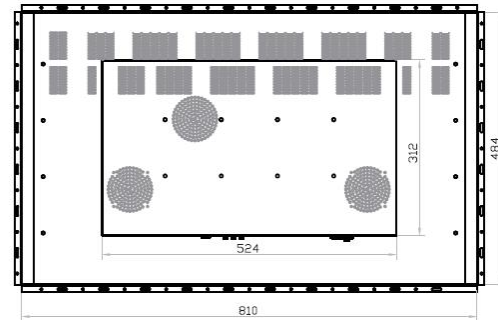



# ID-32Pw 32" Widescreen Open Frame LCD Panel

## Dimension Drawings (mm)

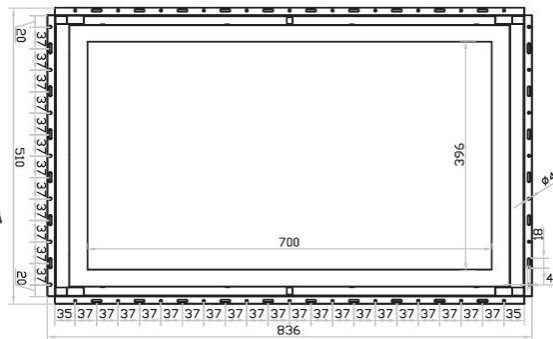

### Applications

- Industrial process control
- Point of sales / Kiosk
- Security / Surveillance
- Flight information display

### Options


- TV tuner

### Design features

- Universal open frame mounting for various applications
- OSD control keys & remote controller to optimize the display
- Support Picture in Picture ( PIP )
- Built-in video input ( HDMI, Component, S-Video & RCA )
- Built-in audio input with speaker

## Specifications

### LCD Panel

Panel Grading	 Class A TFT LCD panel
Panel Size (in.)	Wide 32" ( 16 : 9 )
Optimum Resolution	1366 x 768
Display Color	16.7M
Brightness-nits (cd/m <sup>2</sup> )	500
Contrast Ratio	1200 : 1
Pixel Pitch (mm)	0.511 x 0.17
Viewing Angle (L/R/U/D)	89 / 89 / 89 / 89
OSD Control	Brightness, Contrast, Phase & Clock, Color, H & V position, Auto-tune & Recall
Connector(s)	D-Sub 15 pin VGA analog
LCD Panel MTBF (hrs)	50,000
Power	100~240VAC via AC adapter
Mounting	VESA-mount, Open frame kit and Optional OEM mounting design
Dimensions (mm)	836 x 117 x 510 (W x D x H)

### Operating Temperature

0° to 50° C

### Storage Temperature

-5° to 60° C

### Humidity

5~90%, non-condensing

### Shock

10G peak acceleration  
(11ms duration)

### Vibration

5-500Hz, 1G RMS random vibration

## Ordering information

Model no.	Description
ID-32Pw	Wide 32" open frame LCD panel with VGA, HDMI, Component, S-Video & RCA input, audio input with speaker
ID-32PwTV	Wide 32" open frame LCD panel with VGA, HDMI, Component, S-Video & RCA input, TV tuner, audio input with speaker