


ID-40Aw 40" Widescreen Front Aluminum LCD Panel

Dimension Drawings (mm)

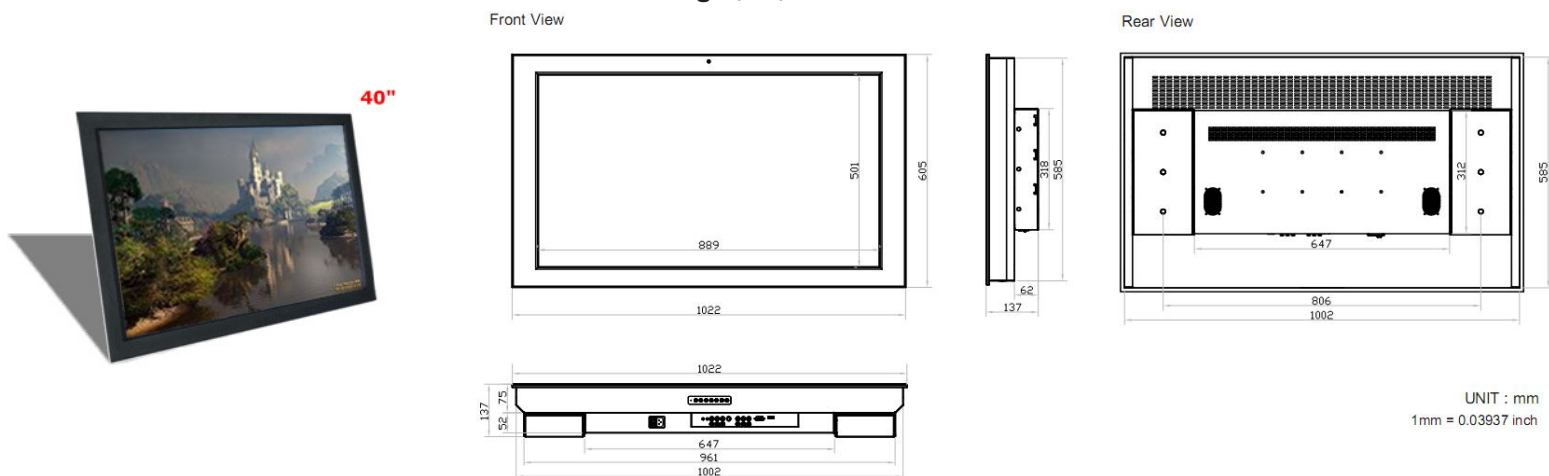

Applications

- Industrial process control
- Point of sales / Kiosk
- Security / Surveillance
- Flight Information display panel

Options

- TV tuner
- Quad Display
- NEMA4 / IP65 2mm Protective Glass

Design features

- OSD control keys & remote controller to optimize the display
- Support Picture in Picture (PIP)
- Built-in VGA & HDMI input
- Built-in video input (Component, S-Video & RCA)
- Built-in audio input with speaker

Specifications

LCD Panel	
Panel Grading	Class A TFT LCD panel
Panel Size (in.)	Wide 40" (16 : 9)
Optimum Resolution	1366 x 768
Display Color	16.7M
Brightness-nits (cd/m ²)	500
Contrast Ratio	2000 : 1
Pixel Pitch (mm)	0.648 x 0.216
Viewing Angle (L/R/U/D)	89 / 89 / 89 / 89
OSD Control	Brightness, Contrast, Phase & Clock, Color, H & V position, Auto-tune & Recall
Connector(s)	D-Sub 15 pin VGA analog
LCD Panel MTBF (hrs)	50,000
Power	100~240VAC via AC adapter
Mounting	VESA-mount, Wall-mount, Mounting bracket and OEM mounting design
Dimensions (mm)	1022 x 137 x 605 (W x D x H)

Operating Temperature	0° to 50° C
Storage Temperature	-5° to 60° C
Humidity	5~90%, non-condensing
Shock	10G peak acceleration (11ms duration)
Vibration	5-500Hz, 1G RMS random vibration

Ordering information

Model no.	Description
ID-40Aw	Wide 40" front aluminum LCD panel with VGA, HDMI, Component, S-Video & RCA input, audio input with speaker
ID-40AwTV	Wide 40" front aluminum LCD panel with VGA, HDMI, Component, S-Video & RCA input, TV tuner, audio input with speaker
-IP65	Add NEMA4 / IP65 Protective Glass