


ID-40Dw 40" Widescreen Stylish Front Aluminum Cover LCD Panel

Dimension Drawings (mm)

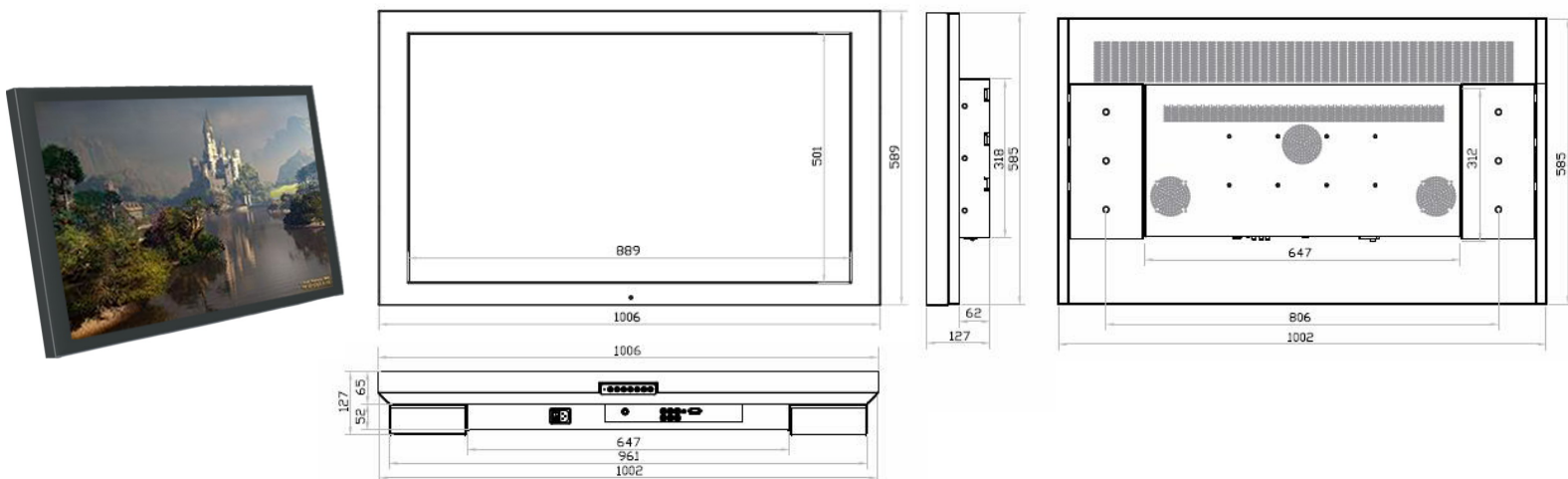

Applications

- Industrial process control
- Point of sales / Kiosk
- Security / Surveillance
- Flight information display

Options

- TV tuner

Design features

- 1.2mm aluminum front cover
- OSD control keys & remote controller to optimize the display
- Support Picture in Picture (PIP)
- Built-in video input (HDMI, Component, S-Video & RCA)
- Built-in audio input with speaker

Specifications

LCD Panel



Panel Grading	Grade A industrial TFT LCD panel
Panel Size (in.)	Wide 40" (16 : 9)
Optimum Resolution	1366 x 768
Display Color	16.7M
Brightness-nits (cd/m ²)	500
Contrast Ratio	2000 : 1
Pixel Pitch (mm)	0.648 x 0.216
Viewing Angle (L/R/U/D)	89 / 89 / 89 / 89
OSD Control	Brightness, Contrast, Phase & Clock, Color, H & V position, Auto-tune & Recall
Connector(s)	D-Sub 15 pin VGA analog
LCD Panel MTBF (hrs)	50,000
Power	100~240VAC via AC adapter
Mounting	VESA-mount, Optional OEM mounting design
Dimensions (mm)	1006 x 127 x 589 (W x D x H)

Operating Temperature

0° to 50° C

Storage Temperature

-5° to 60° C

Humidity

5~90%, non-condensing

Shock

10G peak acceleration
(11ms duration)

Vibration

5-500Hz, 1G RMS random vibration

Ordering information

Model no.	Description
ID-40Dw	Wide 40" stylish front aluminum cover LCD panel with VGA, HDMI, Component, S-Video & RCA input, audio input with speaker
ID-40DwTV	Wide 40" stylish front aluminum cover LCD panel with VGA, HDMI, Component, S-Video & RCA input, TV tuner, audio input with speaker