




Toll Free : 1-888-865-6888

Tel : 510-226-8368 Fax : 510-226-8968

Email : sales@RackmountMart.com

LCD1U10-01 1U COMPACT 10.4" TFT LCD KB DRAWER

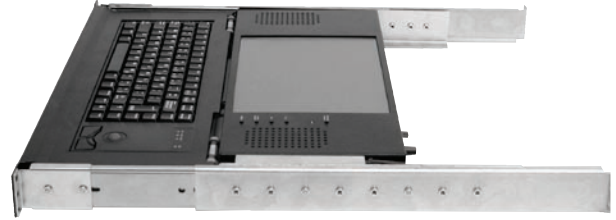

- Display, keyboard, trackball or touchpad and optional speakers in 1U of rack space for 19" racks.
- Mounted with included smooth action ball bearing slides which lock in the extended position.
- Display powers off preserving back light life when tilted down for sliding into the rack.
- Optional integrated amplified speakers and/or composite and S-Video inputs.
- Retainer and lock options to keep unit contained in the rack when not in use.
- Housed in rugged steel construction with a durable powder coat finish.



DISPLAY SPECIFICATIONS

Display Type:	Active matrix TFT LCD	Resolution:	640 x 350 640 x 480 800 x 600 1024 x 768
Colors:	262K colors	Display Area:	10.4" Diagonal
Contrast Ratio:	600:1 typ.	Horizontal Frequency:	31.5 to 80 KHz
Brightness:	190 cd/m ² typ.	Vertical Frequency:	56 to 75 Hz.
Viewing Angle:	178° (H)/178° (V)	Surface Treatment:	Anti-glare/Hard coat.
Response Time:	25ms (typ).		

GENERAL SPECIFICATIONS

Dimensions:	19.0" (W) x 1.75" (H) x 14.50" (D)
Weight:	27 lbs
Power (TFT Display):	90 - 260 VAC, 50/60 Hz. 60 Watts maximum
On-Screen Controls:	Brightness, Contrast, Horizontal & Vertical Position, Auto Adjust, OSD H & V Position, Load and Save Values
Plug & Play:	DDC1 and DDC2B
Temperature:	Operating: 0°C to 50°C Storage: -20°C to 60°C
Humidity:	Operating: 10 to 85% RH (max)
Input Signal (VGA):	R.G.B. analog video, TTL H & V sync.
Input Connector:	Display: 15-pin mini D-Shell
Colors Available:	Black.

KEYBOARD AND MOUSE SPECIFICATIONS

Rollover:	Alpha N-key rollover.
Auto repeat:	Yes.
Self Diagnostics:	At power on and system reset.
Data Buffer:	All codes buffered before sending.
Operating voltage:	+5 VDC +/- 5%.
Operating current:	100 mA max.
Trackball Size:	16mm.
Touchpad Size:	2.1" X 1.25"
Buttons:	Left and Right, Scroll(touchpad).
Interface:	Keyboard: PS/2. Trackball: PS/2. Touchpad: PS/2.
Compatibility:	DOS, Windows 3.X, Windows 95/98, Windows NT, Windows 2000,XP. Specifications subject to change without notice.

***This unit is recommended for use
with KVM switches.***

*Contact us about other options and
our additional rack mount products.*

