


LCD1U15-014/17-013/19-012 1U LCD Rackmount Short Depth Drawer



Flip up design

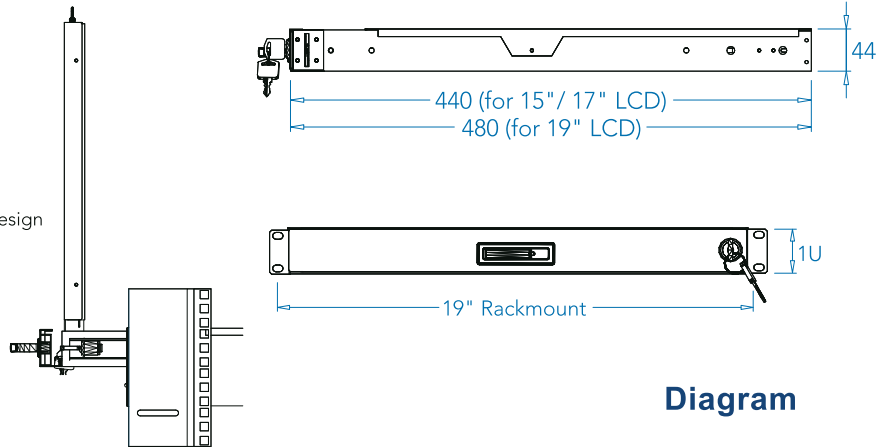

Diagram

Unit : mm

Options:



AV Input



DVI Input



BNC Input



DC Power Input



Touch Screen

Designed for:



Drawer Features & Options

- 1U rackmount LCD drawer with either 15", 17" or 19" SAMSUNG LCD
- Multi lingual on screen display menu
- AV Composite Video, S-Video, DVI and BNC input options
- 12, 24 and 48 volt DC power options

LCD Drawer Benefits

- ▶ Short depth design of 440mm / 480mm (17.3" / 18.9") only
- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed

Monitor Grade A industrial TFT LCD panel

- 15" 1024 x 768 LCD with 250 nit brightness and 700:1 contrast ratio typical
- 17" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" 1280 x 1024 LCD with 300 nit brightness and 1000:1 contrast ratio typical

Ordering Information

	15" LCD Series	17" LCD Series	19" LCD Series
Model	LCD1U15-014	LCD1U17-013	LCD1U19-012

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U15-014	442 x 440 x 44 mm 17.4 x 17.3 x 1.73 inch	10 kg / 22 lbs
LCD1U17-013	442 x 440 x 44 mm 17.4 x 17.3 x 1.73 inch	12 kg / 26 lbs
LCD1U19-012	442 x 480 x 44 mm 17.4 x 18.9 x 1.73 inch	13 kg / 29 lbs