 





S-Video + BNC




Touchscreen - USB



 DVI-D



Touchscreen - Serial

 

DC Power



Audio



Options



BNC + S-Video



DVI-D



DC Power



Touch Screen



Audio



Quad Display

Drawer Features & Options

- 1U rackmount LCD drawer with either 17" or 19" LCD
- Quad display option
- Touchscreen option
- 12V, 24V and 48V DC Power options
- AV + BNC, Audio and DVI-D options

LCD Drawer Benefits

- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed
- ▶ "One Man" installation slides for easy, quick installation
- ▶ Enhanced aesthetics with new molded front panel and two point lock

Monitor  Grade A 17" or 19" industrial TFT LCD panel

- 17" LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" LCD with 300 nit brightness and 1000:1 contrast ratio typical

Ordering Information


17" LCD Series

19" LCD Series

| | | |
|-------|-------------|-------------|
| Model | LCD1U17-011 | LCD1U19-011 |
|-------|-------------|-------------|

Diagram

Unit : mm

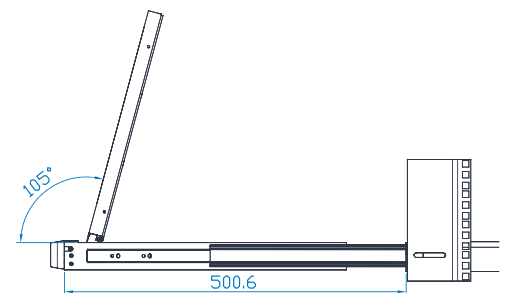

Dimensions

| Model | Product Dimension (W x D x H) | Net Weight |
|-------------|--|----------------|
| LCD1U17-011 | 446 x 600 x 44 mm 17.6 x 23.6 x 1.73 inch | 12 kg / 26 lbs |
| LCD1U19-011 | 446 x 600 x 44 mm 17.6 x 23.6 x 1.73 inch | 13 kg / 29 lbs |