



Options



DVI-D

 


DC Power

DVI-D




DC Power



Diagram

Unit : mm

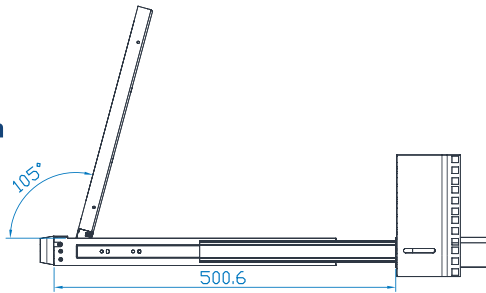

Drawer Features & Options

- 1U rackmount LCD drawer with either 17" or 19" LCD
- DVI-D option
- 12V, 24V and 48V DC Power options

LCD Drawer Benefits

- ▶ Sliding LCD allowing LCD to remain open when the rack door is closed
- ▶ Direct Support for SUN Micro 1152 x 900 native resolution
- ▶ "One Man" installation slides for easy, quick installation
- ▶ Enhanced aesthetics with new molded front panel and two point lock

Monitor  Grade A 17 or 19" industrial TFT LCD panel

- 17" LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 19" LCD with 300 nit brightness and 1000:1 contrast ratio typical
- 1280 x 1024 native graphic resolution
- Video auto-adjust for optimum image

Ordering Information

	17" LCD Series	19" LCD Series
Model	LCD1U17-014	LCD1U19-013

Dimensions

Model	Product Dimension (W x D x H)	Net Weight
LCD1U17-014	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	12 kg / 26 lbs
LCD1U19-013	442 x 600 x 44 mm 17.4 x 23.6 x 1.73 inch	13 kg / 29 lbs